

Delock LTE Antenna N Plug 2.5 dBi Omnidirectional Fix White Outdoor

Description

This LTE antenna by Delock allows the usage of different LTE bands outside. It is completely compatible to GSM, UMTS, ZigBee, Z-Wave, NB-IoT, WLAN 2.4 GHz, Bluetooth, ISM and LoRa.



Item no. 88980

EAN: 4043619889808

Country of origin: Taiwan,
Republic of China

Package: Retail Box

Technical details

- Connector: 1 x N plug
- Frequenzbereich:
 - 698 - 791 MHz
 - 824 - 960 MHz
 - 1710 - 2170 MHz
 - 2500 - 2700 Mhz
- Gain: 0.5 - 2.5 dBi
- Impedance: 50 Ohm
- Operating temperature: -40 °C ~ 70 °C
- Housing: ABS UV protect
- Dimensions (LxØ): ca. 166.5 x 18.3 mm
- Diameter N plug: 22.5 mm


System requirements

- Device with a free N connector

Package content

- LTE antenna

Images

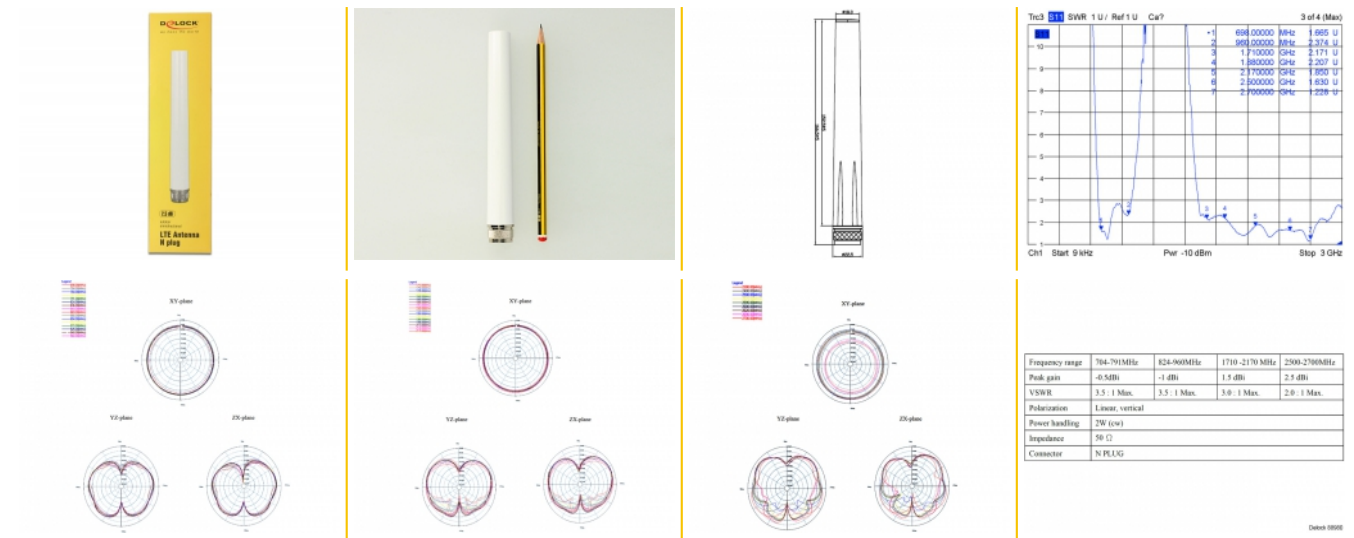

General

Mounting type:	Screw mounting
Suitable for outdoor:	yes

Interface

Connector:	1 x N male
------------	------------

Technical characteristics

Frequency range:	824 - 960 MHz 2500 - 2700 MHz 1710 - 2170 MHz 698 - 791 MHz
Antenna gain:	0,5 - 2,5 dBi
Impedance:	50 Ω
Operating temperature:	-40 °C ~ 70 °C
VSWR:	< 3.5

Physical characteristics

Housing material:	ABS UV resistant
Diameter:	18.30 mm
Length:	166.5 mm
Colour:	white

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

