

Keystone Module RJ45 jack to LSA Cat.6A toolfree 90° angled shielded for cable diameter from 6.0 - 8.5 mm

Description

This module by Delock can be used to connect a network cable and is suitable for easy snap-in mounting in various holders, such as keystone patch panels, face plates or surface-mount boxes.

Flexible 90° connection

The module has an angled cable guide that can be adjusted at a 90° angle depending on the installation situation. This is particularly practical when there is little space available, for example in narrow junction boxes or distribution panels. This allows cables to be laid neatly and without sharp bends.



Item no. 90374

EAN: 4043619903740

Country of origin: China

Package: Zip poly bag

Technical details


- Connectors:
1 x RJ45 jack
1 x LSA (toolfree)
- Cat.6A specification
- 90° angled cable routing
- Shielded
- TIA-568A/B pinout
- For solid or stranded wire (24 - 22 AWG)
- For cable diameter from 6.0 - 8.5 mm
- For Keystone ports with 19.2 x 14.9 mm
- Material: zinc diecast
- Dimensions (LxWxH): ca. 38.5 x 16.1 x 19.6 mm

Package content

- Keystone module
- 90° angled cable routing
- Cable manager
- Cable gland

- Copper strip

Images

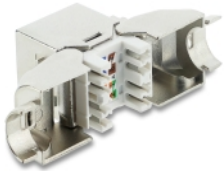

General

Specification:	Cat. 6A
----------------	---------

Interface

Connector 1:	1 x RJ45 jack
Connector 2:	1 x LSA (toolfree)

Physical characteristics

Cable gauge:	24 - 22 AWG
Material:	zinc die cast
Shielding:	shielded
Length:	38,5 mm
Width:	16.1 mm
Height:	19.6 mm
Cable diameter:	6.0 - 8.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

