


Cable with a fork terminal

Connector	Colour	H05V-K050	H05V-K075	H05V-K100	H07V-K150	H07V-K250	H07V-K400
M4WI	red	M4WI-050RD025	M4WI-075RD025	M4WI-100RD025	M4WI-150RD025	M4WI-250RD025	M4WI-400RD025
M4WI	black	M4WI-050BK025	M4WI-075BK025	M4WI-100BK025	M4WI-150BK025	M4WI-250BK025	M4WI-400BK025
M4WI	yellow-green	M4WI-050YG025	M4WI-075YG025	M4WI-100YG025	M4WI-150YG025	M4WI-250YG025	M4WI-400YG025
M5WI	red	M5WI-050RD025	M5WI-075RD025	M5WI-100RD025	M5WI-150RD025	M5WI-250RD025	M5WI-400RD025
M5WI	black	M5WI-050BK025	M5WI-075BK025	M5WI-100BK025	M5WI-150BK025	M5WI-250BK025	M5WI-400BK025
M5WI	yellow-green	M5WI-050YG025	M5WI-075YG025	M5WI-100YG025	M5WI-150YG025	M5WI-250YG025	M5WI-400YG025
M6WI	red	M6WI-050RD025	M6WI-075RD025	M6WI-100RD025	M6WI-150RD025	M6WI-250RD025	M6WI-400RD025
M6WI	black	M6WI-050BK025	M6WI-075BK025	M6WI-100BK025	M6WI-150BK025	M6WI-250BK025	M6WI-400BK025
M6WI	yellow-green	M6WI-050YG025	M6WI-075YG025	M6WI-100YG025	M6WI-150YG025	M6WI-250YG025	M6WI-400YG025

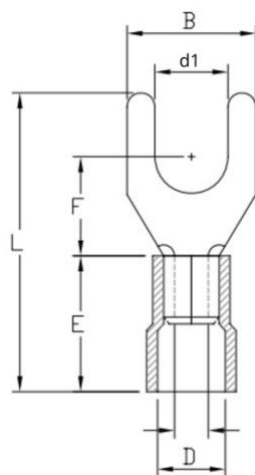

Connector	Wire Range (mm2)	Screw	Insulated colour	d1 (mm)	D (mm)	L (mm)	B (mm)	F (mm)	E (mm)
M4WI-050/075/100	0,5-1,0	M4	red	4,3	4,3	21,5	7,2	6,3	10,5
M5WI-050/075/100	0,5-1,0	M5	red	5,3	4,3	21,5	9,5	7,0	10,5
M6WI-050/075/100	0,5-1,0	M6	red	6,4	4,3	27,7	12,0	7,0	10,5
M4WI-150/250	1,5-2,5	M4	blue	4,3	5,0	21,6	6,4	6,5	11,0
M5WI-150/250	1,5-2,5	M5	blue	5,3	5,0	23,0	8,5	7,3	11,0
M6WI-150/250	1,5-2,5	M6	blue	6,4	5,0	28,2	12,0	7,3	11,0
M4WI-400	4,0-6,0	M4	yellow	4,3	6,7	26,7	9,5	7,5	14,0
M5WI-400	4,0-6,0	M5	yellow	5,3	6,7	26,7	9,5	7,5	14,0
M6WI-400	4,0-6,0	M6	yellow	6,4	6,7	32,7	13,5	7,5	14,0

The standard cable length is 250mm

if you need another colour/length
please ask dso@tme.pl

