
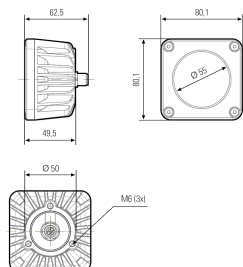
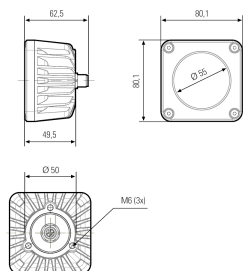


## LED Maschinenleuchte

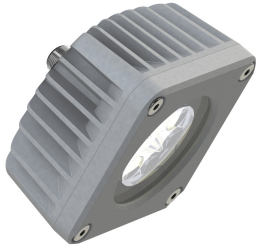

|                                   |                                                                   |
|-----------------------------------|-------------------------------------------------------------------|
| <b>Product-Nr.</b>                | 121011-04                                                         |
| <b>EAN:</b>                       | 4260556625713                                                     |
| <b>Model:</b>                     | CENALED SPOT Aufbau                                               |
| Order number:                     | 121011-04                                                         |
| <b>Model:</b>                     | CENALED SPOT Aufbau                                               |
| <b>Type:</b>                      | surface-mounted LED light                                         |
| <b>Illuminant:</b>                | High Power LED                                                    |
| <b>Power consumption:</b>         | ~8,5 W                                                            |
| <b>Lamp luminous flux:</b>        | 1120 lm                                                           |
| <b>Lamp luminous efficiency:</b>  | 134 lm/W                                                          |
| <b>Light distribution:</b>        | direct                                                            |
| <b>Light colour:</b>              | neutral white (5000K)                                             |
| <b>Connected load:</b>            | 24V DC $\pm$ 10%                                                  |
| <b>Connection (connector):</b>    | M12 A-coded                                                       |
| <b>Degree of protection:</b>      | IP67                                                              |
| <b>Class of protection:</b>       | III                                                               |
| <b>Beam angle (optics):</b>       | 15°                                                               |
| <b>Operating temperature:</b>     | -10... +50 °C                                                     |
| <b>Colour rendering (Ra):</b>     | >80                                                               |
| <b>Lamps lifetime:</b>            | > 60.000 h (L80/B10)                                              |
| <b>Housing material:</b>          | aluminium (powder-coated)                                         |
| <b>Cover material:</b>            | safety glass 4 mm (0,16"), crack-resistant                        |
| <b>Height [B] x Width [C]:</b>    | cubic measure: ~80 mm x 80 mm x 62.5 mm<br>(~3,15 x 3,15 x 2,46") |
| <b>Weight (net):</b>              | 400 g (~14 oz)                                                    |
| <b>Gross weight:</b>              | 500 g (~18 oz)                                                    |
| <b>Risk group (DIN EN 62471):</b> | free group                                                        |
| <b>Markings:</b>                  | CE, UKCA, ETL Listed (5003526)                                    |
| <b>Dimmable:</b>                  | optional via accessories                                          |
| <b>Mounting accessories:</b>      | articulated joint 214300-01 as holder optional                    |
| <b>Made in:</b>                   | Germany                                                           |
| <b>Feature:</b>                   | 15° optics for spot light                                         |
| <b>Note:</b>                      | seal included; mounting: 3x M6 screws at rear                     |