

M.2 Docking Station for 2 x M.2 SATA SSD with Clone function

Description

This M.2 docking station by Delock enables the installation of **two M.2 SATA SSDs** and it can be connected via USB to the PC or laptop. The included USB cable allows the connection to a free **USB-C™** port.

M.2 SATA SSD clone function

The clone function enables to **copy the content of one SSD to another** without using a PC.


Ideal test equipment

The memory is simply plugged into the robust housing and can be used immediately. No screws, tools or accessories are required, which means that the SSD can be changed quickly.

Please Note

There is no support for PCIe NVMe M.2 SSD.

For a sufficient power supply, it is necessary to use the included power supply. Otherwise, the docking station will not function if the power supply (power supply or USB port) is too low.

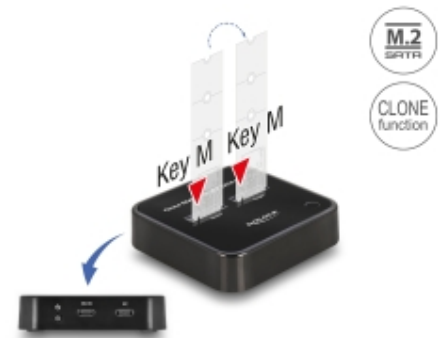

Item no. 64178

EAN: 4043619641789

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB 10 Gbps USB Type-C™ female
 - 2 x M.2 key M slot
 - 1 x USB Type-C™ female (power supply)
- Chipset: Asmedia ASM1352R, VIA VL160
- Supports M.2 modules with key B+M based on SATA
- Data transfer rate up to 6 Gbps
- Supports UASP
- LED indicator for power, access and copy status
- Function key:
 - 1 x Clone button
 - 1 x On / Off switch
- Bootable
- Dimensions (LxWxH): ca. 72 x 79 x 18 mm

- Hot Plug, Plug & Play

Power supply specification

- Wall power supply
- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 0.6 A
- Output: 5.0 V / 3.0 A

System requirements

- Android 10.0 or above
- Chrome OS 83.0 or above
- iPad Pro (2018)
- Linux Kernel 5.4 or above
- Mac OS 10.15.6 or above
- Windows 8.1/8.1-64/10/10-64/11
- Device with a free USB Type-C™ port or with a free Thunderbolt™ 3 port

Package content

- M.2 docking station
- Cable USB-C™ male to USB-C™ male, length ca. 45 cm
- Cable USB-C™ male to USB Type-A male, length ca. 80 cm (power supply)
- External power supply
- User manual

Images



General

Function:	Clone Function
Supported operating system:	Chrome OS 83.0 or above Linux Kernel 5.4 or above Mac OS 10.15.6 or above Windows 10 32-Bit Windows 10 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit iPad Pro (2018) Android 10.0 or above Windows 11
Slot:	SATA
Maximum height of the components on the module:	1.5 mm application of double-sided assembled modules supported

Interface

Connector 1:	1 x USB 10 Gbps USB Type-C™ female
Connector 2:	2 x 67 pin M.2 key M slot
Connector 3:	1 x USB Type-C™ female (power supply)

Technical characteristics

Data transfer rate:	10 Gbps
---------------------	---------

Physical characteristics

Length:	79 mm
Width:	72 mm
Height:	18 mm
Colour:	black

Manufacturer information

Street Beeskowdamm 13/15
Postal code 14167

City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de