


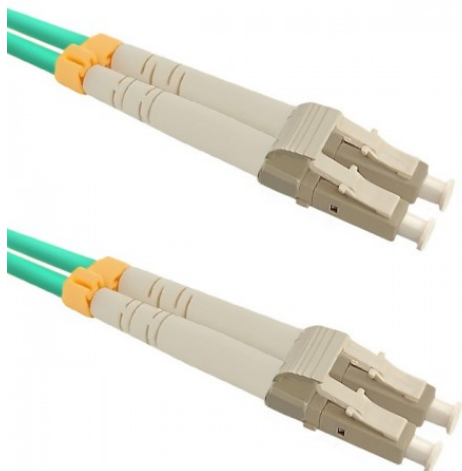

Patchcord fiber optic LC/UPC - LC/UPC | Multimode | 50/125 | OM3 | Duplex | 50m

Product code: 54083

Patchcord fiber optic multimode
Connectors: LC/UPC - LC/UPC
Standard: OM3
Diameter cable: 3.0 mm
Cable length: 50 m

Technical data

Type connectors	LC/UPC - LC/UPC
Type patchcord	Multimode
Type of fiber optic transmission	Duplex
Standard fiber	OM3
Fiber type	50/125
Sheath	LSZH
Diameter cable	3.0 mm
Insertion loss	<0.3 dB
Return loss	35 - 39 dB
Cable length	50 m
Reinforcing element	Aramid fiber
Colour	Aqua
Additional information	Easy installation and handling on high speed fiber optical transmission networks. LSZH - Outside fireproof cable sheath, which the fire does not emit harmful gases. The product individually tested.
Package	Polybag
Gross weight	0,666 kg
EAN code	5901878540832

	100 Mb Ethernet	1 Gb Ethernet	10 Gb Ethernet	40 Gb Ethernet	100 Gb Ethernet
OM2 (50/125)	2km	550m	82m	Nie wspiera	Nie wspiera
OM3 (50/125)	2km	800m	300m	100m	100m
OM4 (50/125)	2km	1100m	550m	125m	125m