

# DIGITUS® Single monitor mount, 27", 8 kg

DA-90361

EAN 4016032424819



## Single Monitor Desk Clamp Mount, 15-27", black max. load 8Kg, VESA max. 100x100

Universal monitor stand for flexible positioning of your monitor at the workstation with simple horizontal and vertical tilting and swivel options. Simply adjust the viewing height to suit your requirements. The monitor stand enables the mounting of LED and LCD monitors of all brands. Simply note the VESA dimensions and the weight of your monitors to select a suitable stand.

### Universal single monitor clamp mount up to 69cm (27")

- Suitable for VESA standard distances 75 x 75 and 100 x 100 mm
- Maximum load capacity up to 8 kg
- For monitors up to 69cm (27") and 8kg maximum weight
- Freely adjustable vertical tilt angle up to 45 degrees
- Can be freely swiveled by 45
- Rotates 360°

- Weight: 3.3 kg
- Dimensions: 490 x 550 x 116 mm
- Tested & certified ergonomic product - Certified by IGR (Institute for Health and Ergonomics)

### Attributes


- Monitor weight (max.): 8 kg
- Mounting method: Clamp-mount
- Number of monitors: 1
- Size of monitors: up to 27"
- VESA mount: 75x75 mm, 100x100 mm

### Package contents

- Monitor stand
- Screws for monitor mounting
- Operating instructions

| Logistics                    |              |             |            |            |             |           |
|------------------------------|--------------|-------------|------------|------------|-------------|-----------|
|                              | Number (pcs) | Weight (kg) | Depth (cm) | Width (cm) | Height (cm) | cm³       |
| Packaging Unit Carton        | 4            | 15.80       | 49.50      | 34.00      | 24.00       | 40,392.00 |
| Packaging Unit Inside        | 1            | 3.95        | 47.80      | 16.30      | 11.00       | 8,570.54  |
| Packaging Unit Single        | 1            | 3.95        | 47.80      | 16.30      | 11.00       | 8,570.54  |
| Net single without Packaging | 1            | 3.41        | 47.80      | 16.30      | 11.00       | 8,570.54  |

## More images:

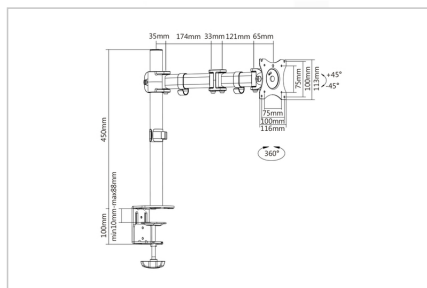

## Safety notes

- Please read the entire manual before starting assembly and installation. Please contact your local dealer if you have any questions about the instructions or warnings.
- CAUTION: Use with products that exceed the permitted weight may result in damage or possible injury.
- Brackets should be fitted in accordance with the installation instructions. Incorrect installation can result in damage or injury.
- Use safety equipment and suitable tools. The product should only be installed by specialists.
- This product can be installed on timber-framed, solid concrete or stone walls.
- The load-bearing surfaces should be able to safely withstand the entire weight of appliances and all additional components.
- Only use the installation screws supplied and DO NOT TIGHTEN the screws TOO TIGHT.
- This product contains small parts that can cause a choking hazard if swallowed. Keep these parts away from children.
- Only use this product indoors. Using the product outdoors can lead to injury and damage.
- IMPORTANT: Before installation, please check all components received against the components list. If parts are damaged or missing, ask your local dealer for replacement parts.
- MAINTENANCE: Check the bracket regularly for safety and stability (preferably every three months).

## EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH  
Auf dem Schüffel 3  
Lüdenscheid, Germany  
<https://www.assmann.com>  
[info@assmann.com](mailto:info@assmann.com)