

# USB 10 Gbps FPC Flat Ribbon Cable USB Type-C™ to USB Type-C™ 22 cm PD 3 A E-Marker

## Description

This USB cable by Delock enables the connection between a device with a USB Type-C™ connector and a PC or a laptop equipped with a free USB Type-C™ port.

### Ultra flexible cable

The cable is characterized by its special construction. Instead of normal copper wires there is a flexible circuit board inside the cable, which is also called FPC (Flexible Printed Circuit). This makes the cable extremely flexible and yet robust. It is particularly suitable for charging smartphones via a power bank on the go.



22 cm

**Item no. 85926**

EAN: 4043619859269

Country of origin: China

Package: Zip poly bag

## Technical details

- Connectors:
  - 1 x USB 10 Gbps USB Type-C™ male
  - 1 x USB 10 Gbps USB Type-C™ male
- Chipset: Fresco Logic E-Marker
- FPC (Flexible Printed Circuit) flat ribbon cable
- Output current: up to 3 A
- Cable thickness: ca. 2 mm
- Data transfer rate up to 10 Gbps
- Colour: silver / black
- Length incl. connectors: ca. 22 cm

## System requirements


- PC or laptop with a free USB Type-C™ port
- Device with USB Type-C™ port

## Package content

- USB 10 Gbps cable

---

## Images

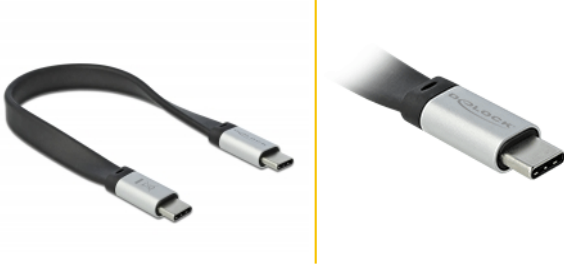

## General

Specification:	USB Type-C™
Style:	both sides identical

## Interface

Connector 1:	1 x USB 10 Gbps USB Type-C™ male
Connector 2:	1 x USB 10 Gbps USB Type-C™ male

## Technical characteristics

Data transfer rate:	10 Gbps
Maximum current:	3 A

## Physical characteristics

Length:	220 mm
Colour:	black silver
Cable diameter:	2 mm

## Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de