

Data sheet Product DH MA 15 UN4




USB / RJ / D-Sub connectors>D-Sub hoods

Features

insulating body material:	zinc die-casting nickel-plated
temperature range:	-40°C... +120°C
class of inflammability:	UL 94 V-0
surface of case:	zinc die-casting nickel-plated

Technical Drawing

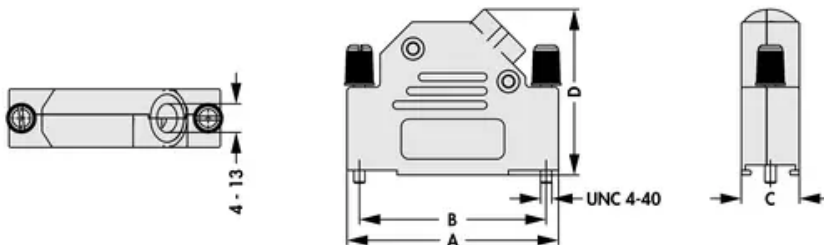

A:	39.5 mm
B:	33.3 mm
C:	14.5 mm
D:	40.3 mm