




DIN 7985 A

~ISO 7045

4.8

Norma ritirata

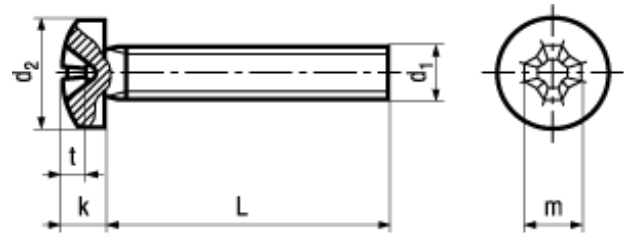

BN 8092

Viti a testa cilindrica bombata

con impronta a croce Phillips forma H

Acciaio 4.8


zincato giallo

- ~UNI 7687
- ~ČSN 021147

[3D Cadenas](#)

Tutte le misure con filettatura quasi completa

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1170309	M2	4	1,72	1	2,5	1,1	1,4	3
1170317								4
1170325								5
1170341								6
1170384								8
1170406								10
1170430								12
1170457								16
1188690	M2,5	5	2,12	1	2,7	1,3	1,6	6
1188704								8
1188712								10
1188720								12
1276190	M3	6	2,52	1	3,1	1,7	2	4
1276204								5
1276212								6
1279823								8
1280066								10
1280236								12
1290665								16
1290770								20
1290797								25
1069845	M4	8	3,25	2	4,6	2,04	2,54	5
1320513								6
1320548								8

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1320572	M4	8	3,25	2	4,6	2,04	2,54	10
1015400								12
1015915								16
1015974								(18)
1016059								20
1016407								25
1033654								30
1033689								40
1033891								50
3092862								80
1365967	M5	10	3,95	2	5,3	2,77	3,27	6
1366157								8
1366173								10
1366254								12
1366289								16
1366912								20
1366920								25
1366939								30
1367021								40
1367390								50
1367439	M6	12	4,75	3	6,8	3,03	3,53	10
1367447								12
5522910								16
1367471								20
3092293								25
1367501								30