


Home - Fischerelektronik - LAM 7 K

 fischerelektronik.de/web_fischer/en_GB/VA/LAM7K12512/datasheet.xhtml

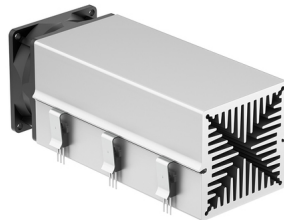

Cooling aggregates>Miniature cooling aggregates

70 x 70 mm, with axial fan, integrated clamp

- compact design
- homogeneous heat distribution
- mounting possible on any side
- powerful axial-fan motor
- other lengths, special designs and machinings according to customer's specifications
- other surfaces, fan types and fan voltages upon request

Features

width:	70 mm
--------	-------


height:	70 mm
---------	-------

length:	125 mm
---------	--------

thermal resistance:	0.67 - 0.15 K/W
---------------------	-----------------

surface:	natural colour anodised
----------	-------------------------

Technical Drawing

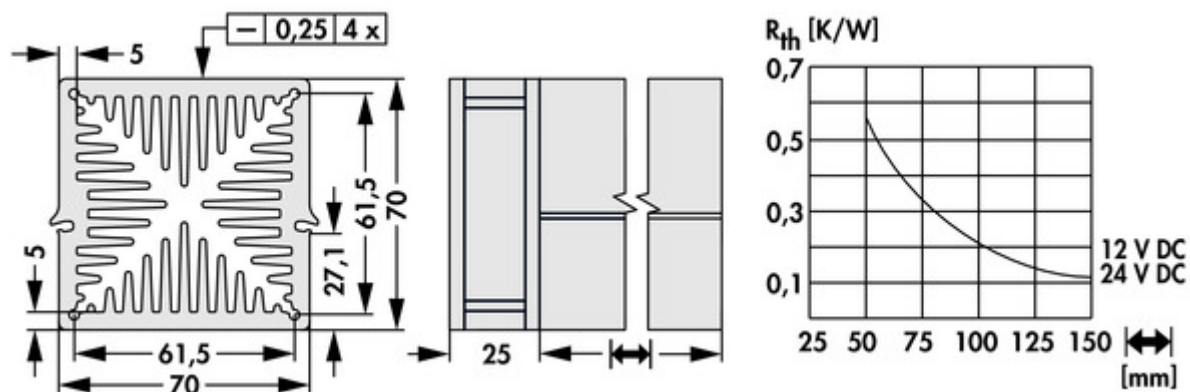

Fan

type: ADDA AD0712UB-A7BGP

dimensions: 70x70x25 mm

tension: 12 V DC

power inout: 5 W

max. air volume: 82 m³/h

temperature range: -10°C... +70°C

speed: 5,000 min⁻¹

noise level: 47.4 dB(A)

weight: 90 g

failure rate (L₁₀): 70.000 h (40°C)

type: ADDA AD0724UB-A7BGP

dimensions: 70x70x25 mm

tension: 24 V DC

power inout:	6.2 W
max. air volume:	82 m ³ /h
temperature range:	-10°C... +70°C
speed:	5,000 min ⁻¹
noise level:	47.4 dB(A)
weight:	90 g
failure rate (L ₁₀):	70.000 h (40°C)

Fischer Elektronik GmbH & Co. KG
 DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
 58511 Lüdenscheid

Telefon +49 2351 435-0
 Telefax +49 2351 45754

info@fischerelektronik.de
 www.fischerelektronik.de