

VK2000L1
CONNECTION TECHNOLOGY • CABLE SOCKETS / CONNECTORS PRE-ASSEMBLED ON ONE SIDE

, 2m, Lemo-mini Female (socket) 3pin Angular, Free conductor end,
3wire, -40-180°C


MECHANICAL FEATURES

Cable infeed of A connection	Angular
Cable length	2 m
Increased ambient temperature > 90°C	+
Number of cores	3
Perm. ambient temperature of cable, fixed cable	-40 °C ... 180 °C
Version	Connection cable

ELECTRICAL FEATURES

Number of pins of A connection	3
Shielded	-
Type of A electrical connection	Lemo-mini
Type of B electrical connection	Free conductor end
Type of plug-in contact, A connection	Female (socket)
With LED display	-

OTHER FEATURES

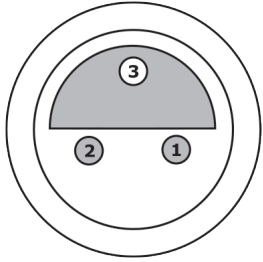
Flame retardant	No
Halogen-free	-
IR-networked	-

Other

Packaging dimensions	160mm x 0.0mm x 220mm
Shipping weight	0.05kg
Tariff code	85444290

Classification

ipf product group	853
eClass 8.0	27279218
eClass 9.0	27060311
eClass 9.1	27060311
ETIM-5.0	EC001855
ETIM-6.0	EC001855
ETIM-7.0	EC001855

Connection

- 1 brown
- 2 black
- 3 blue

Dimensional drawing**Installation**

Mounting / installation may only be carried out by a qualified electrician!

Disposal**Safety warnings**

Before initial operation, please make sure to follow all safety instructions that may be provided in the product information.

Never use these devices in applications where the safety of a person depends on their functionality.

LED lighting systems can generate intensive UV radiation, which can damage your eyes in case of improper use. The manufacturer cannot be held responsible for damages that result from improper use or connection.