

Delock WLAN 802.11 b/g/n Antenna RP-SMA 4 dBi Omnidirectional Flexible Joint ULA100 1 m With Magnetic Stand

Opis

This Wireless LAN antenna can be connected to your device with RP-SMA interface, in order to send and receive signals. Due to the three tilt stages of the flexible antenna and the magnetic stand you can place the antenna individually.



Numer artykułu 88413

EAN: 4043619884131

Kraj pochodzenia:
Taiwan, Republic of
China

Opakowanie: Blister



Szczegóły techniczne

- Omni directional antenna
- RP-SMA screw interface
- With flexible joint – three step
- Compatible to IEEE 802.11n and IEEE 802.11b/g, 802.3, 802.3u, Bluetooth
- Frequency range: 2.4 GHz - 2.5 GHz
- Gain: 4 dBi
- Impedance: 50 Ohm
- Operating temperature: -10°C to +55°C
- 1 m ULA100 connecting cable
- Stand with magnetic and rubberized bottom side
- Dimension: with flexible joint 200 mm, without flexible joint 165 mm

Zawartość opakowania

- WLAN antenna

Zdjęcia

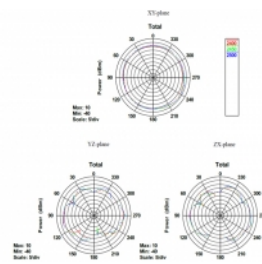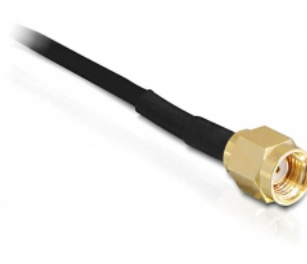

Ogólne

Typ montażu:	magnetic
--------------	----------

Interfejs

Złącze:	1 x męski RP-SMA
---------	------------------

Właściwości techniczne

Zakres częstotliwości:	2400 - 2500 MHz
Siła anteny:	4 dBi
Impedancja:	50 Ω
Temperatura robocza:	-10 °C ~ 55 °C
VSWR:	< 2,0

Właściwości fizyczne

Typ anteny:	wielokierunkowy
Długość kabla ze złączem:	1 m
Długość ze złączem pochylania:	200 mm
Długość bez złącza pochylania:	165 mm

Manufacturer information

Ulica	Beeskowdamm 13/15
Kod pocztowy	14167
Miasto	Berlin
Kraj	Deutschland
Email	info@delock.de
Strona internetowa	www.delock.de

