 

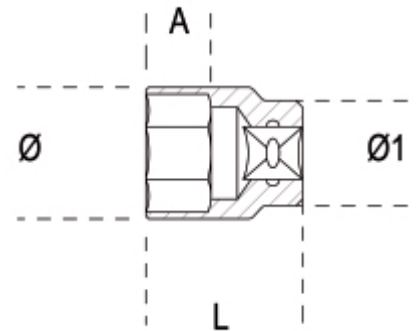


920FTX
hand sockets for Torx® head screws


	Art.	⊙	∅ mm	L mm	∅1 mm	A mm	⚖ g
009200380	920FTX 10	E10	13,2	36	21	6,4	44,8
009200381	920FTX 12	E12	15,0	37	21	8,0	46,4
009200382	920FTX 14	E14	16,3	37	21	8,8	48
009200383	920FTX 16	E16	18,8	37	22	9,6	56,8
009200384	920FTX 18	E18	20,4	37	22	11,1	57,2
009200385	920FTX 20	E20	22,9	37	22	12,7	62,8
009200387	920FTX 22	E22	25,0	37	24	16,5	80
009200388	920FTX 24	E24	26,5	40	25	16,9	95



Scan the QR Code to access the web tab
 Specs, media and documentation in one click.

