


SK9822 RGB Addressable LED strip 5V - 60LEDs/m

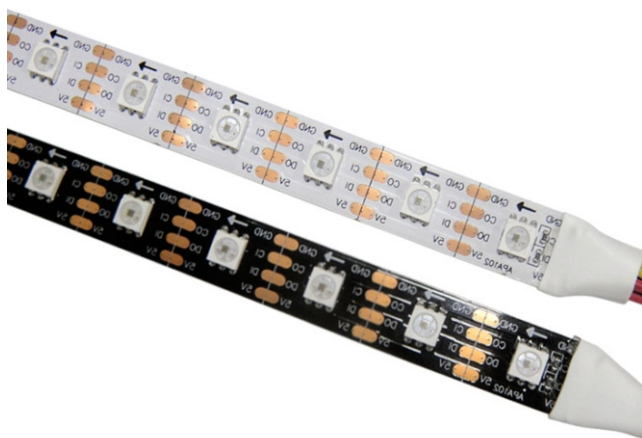

Product Description:

Addressable LED Strip has 60pcs SMD5050 RGB

Built in IC Chips

Each single LED per unit and cut-able every 16.67mm

The PCB is 1+2 Ounce copper, PCB wide is 12mm

All the soldering Pads are very large, with +/-, DAT and CLK

White & Black PCB, DC5V voltage

5 Meters per reel, customized sizes are also available


4Pin JST SM male/female connector

IP Rate: IP20, IP64, IP65

Product Datasheet

Product Number	S012060CA3SA2	Luminance/M	R:24000 G:42000 B:11400lm
Operating Voltage	DC5V	Ra	/
Power/M	15.5W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 12mm
LED Qty/M	60	IP Rate	IP20/IP64/IP65
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	60	Material	FPC
Control	APA102/SK9822	Cutting Length	16.67mm
Wavelength	/	Net Weight/Roll	0.13KG


Outline Dimension (unit: mm)

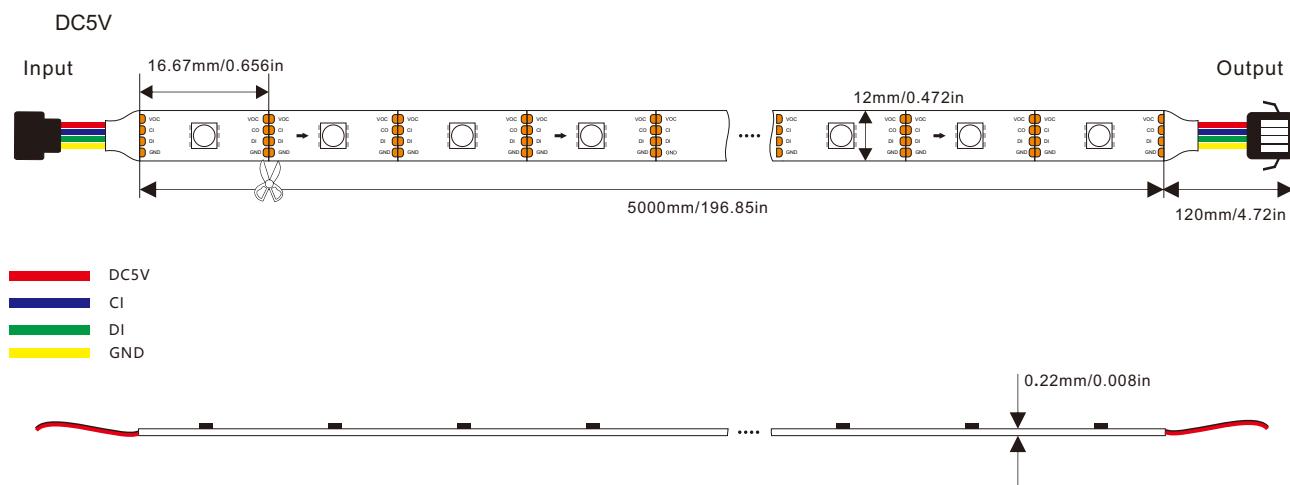


◆ Order number

DC5V	RGB	White PCB	IP20	S012060CA3SA2/C1
DC5V	RGB	Black PCB	IP20	S012060CA3SA2/C2
DC5V	RGB	White PCB	IP64	S012060CA3SA2/C3
DC5V	RGB	Black PCB	IP64	S012060CA3SA2/C4
DC5V	RGB	White PCB	IP65	S012060CA3SA2/C5
DC5V	RGB	Black PCB	IP65	S012060CA3SA2/C6

◆ Wiring diagram

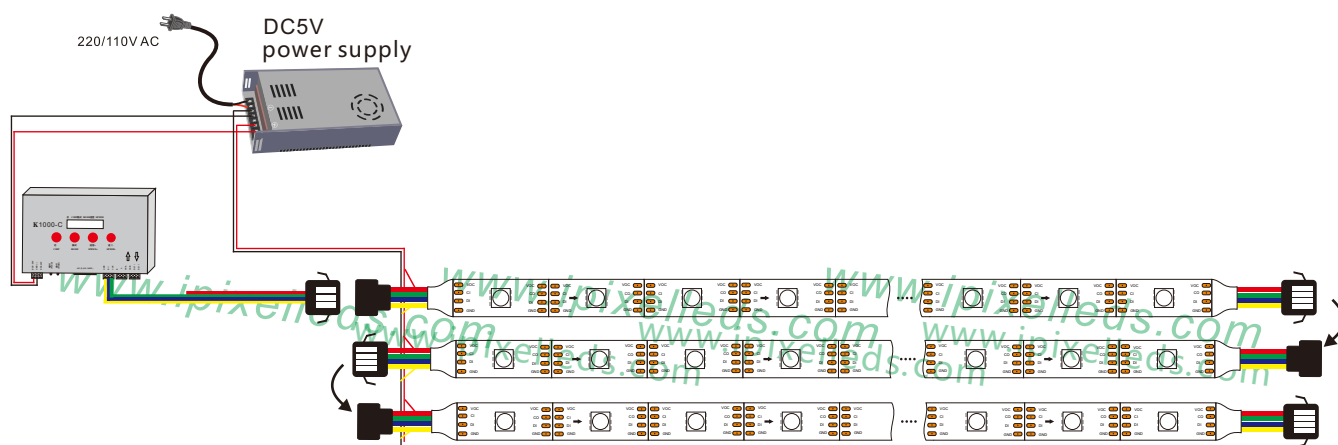

◆ Strip IP Rate

 

◆ Accessories



Screw




Silicone clip



End cap

◆ Schematic diagram of maximum bending prevention

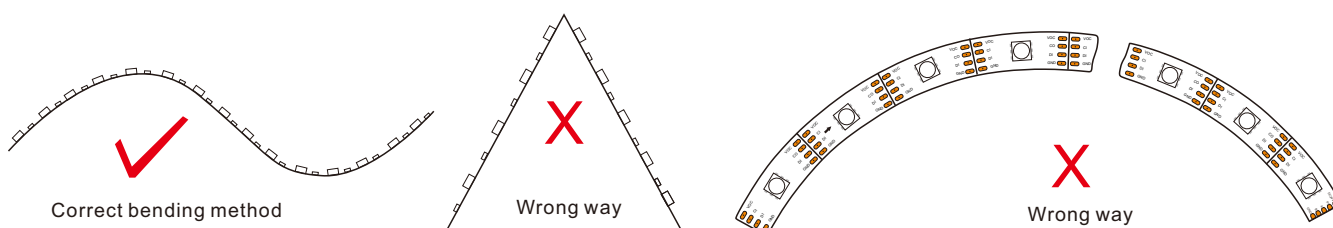

Note: The parameters are subject to change without notice!