

Keystone Module RJ45 jack > LSA Cat.6A STP 24 pieces

Description

This module by Delock can be used to connect twisted pair cable to an RJ45 jack. With its standardised dimensions it can be used for easy snap-in mounting in e.g. a Keystone patch panel, face plate or surface-mount box.



Item no. 86405

EAN: 4043619864058

Country of origin: China

Package: Box


Technical details

- Connectors:
external:
1 x RJ45 jack (8P/8C) >
internal:
LSA (toolfree)
- Cat.6A specification
- Shielded (STP)
- Compliant with Cat.6A requirements of ISO/IEC 11801 Edition 2.2, EN 50173-1:2011 and EN 60603-7-51, and ANSI/TIA 568-C.2
- Material: zinc die cast
- TIA-568A/B pinout
- For solid or stranded wire up to 0.573 mm (23 - 26 AWG)
- For cable diameter from 6.0 - 8.5 mm
- For Keystone ports with 19.2 x 14.9 mm
- Dimensions (LxWxH): ca. 37,8 x 16,0 x 22,5 mm

Package content

- 24 x Keystone module
- 48 x cable manager
- 24 x Zip-tie

Images

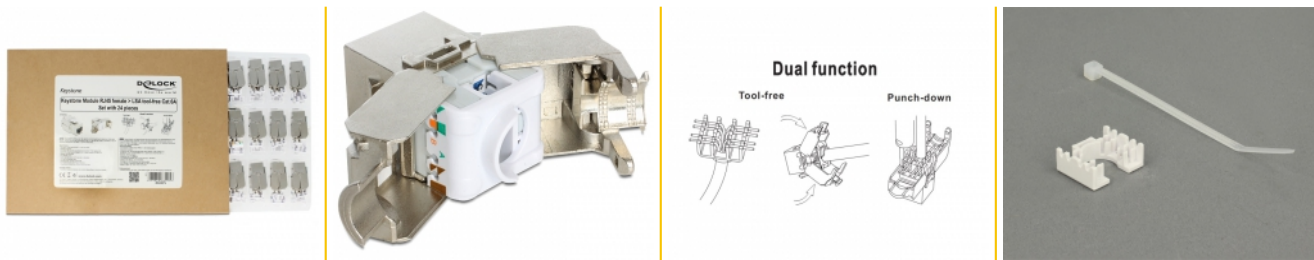

General

Suitable for conductor gauge:	22 - 26 AWG
Mounting type:	Keystone module
Specification:	Cat. 6A

Interface

External:	1 x RJ45 jack
Internal:	1 x LSA block

Physical characteristics

Housing material:	zinc die cast
Shielding:	shielded

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

