

DIGITUS® Flexible wall-mounted Stand/Sit workstation, single monitor

DA-90372

EAN 4016032457442



Sit-Stand Workstation wall single mount, black max load capacity: 1-8 kg,max Screen Size: 17"-32"

Universal wall bracket for mounting a monitor, keyboard/mouse and PC with flexible working height adjustment. Set up a workstation that can be individually adjusted to the working height by many people with just three quick movements despite different body height. The two integrated gas pressure springs ensure very easy height adjustment of a monitor and keyboard tray. When selecting the bracket, please only consider the VESA size and check the weight and dimensions of your monitor for compatibility. A wall-mounted PC bracket is also included.

Universal bracket for mounting a monitor, keyboard and PC on the wall with flexible height adjustment

- Supported monitor sizes: 17" - 32"
- VESA mounting dimensions: 75 x 75, 100 x 100
- Tilt angle: -35° to +35°
- Swiveling: -90° to +90°

- Rotation: 360°
- Monitor load capacity: max. 8 kg
- Keyboard load capacity: max. 1 kg
- PC load capacity: max. 10 kg
- Monitor height adjustment: 1 integrated gas pressure spring
- Height adjustment of keyboard: 1 integrated gas pressure spring
- Integrated cable guide
- Weight: 9.5 kg
- Dimensions: max. L x W x H: 70 x 53 x 94 cm
- Flexible height adjustment of the monitor and keyboard bracket thanks to easy and quick mounting on the support bar

Attributes

- Style: PC Workstation







Package contents

- 1x flexible wall-mounted sit-stand workstation, single monitor - set
- 1x assembly instructions

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	1	10.60	105.00	32.00	16.50	55,440.00
Packaging Unit Inside	1	10.60	105.00	32.00	16.50	55,440.00
Packaging Unit Single	1	10.60	105.00	32.00	16.50	55,440.00
Net single without Packaging	1	9.64	105.00	32.00	16.50	55,440.00

Technical drawings of the 1000 Series 1/2" components. The top left drawing is a side view of a component with dimensions: 17 ± 0.05, 3, 1", 7", 3.5, 20, 9, 90, 1.3, and a 90° angle. The top right drawing is a front view of a component with dimensions: 18.1, 42, 35, 36.3, and a 90° angle. The bottom left drawing is a top view of a component with dimensions: 18.75, 13.5, 20.5, 13.5, 10.75, 2.2, 2.13, 1.3, and a 90° angle. The bottom right drawing is a perspective view of a component with a 90° angle.

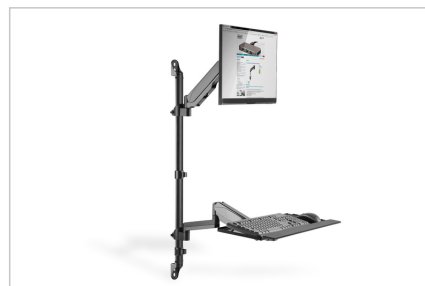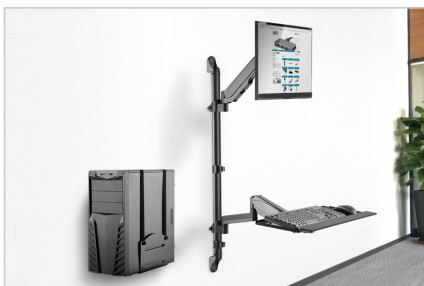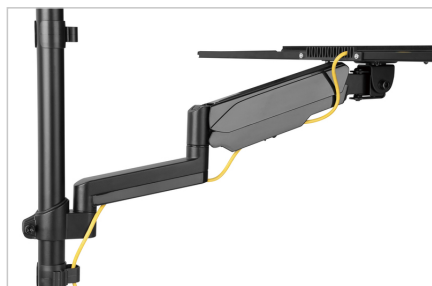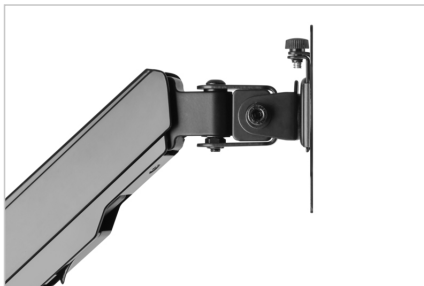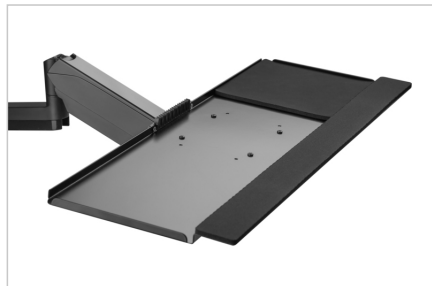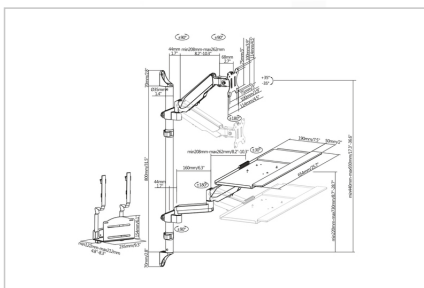

- Please read the entire manual before starting assembly and installation. Please contact your local dealer if you have any questions about the instructions or warnings.
- **CAUTION:** Use with products that exceed the permitted weight may result in damage or possible injury.
- Brackets should be fitted in accordance with the installation instructions. Incorrect installation can result in damage or injury.
- Use safety equipment and suitable tools. The product should only be installed by specialists.
- The load-bearing surfaces should be able to safely withstand the entire weight of appliances and all additional components.
- Only use the installation screws supplied and **DO NOT TIGHTEN** the screws **TOO TIGHT**.
- This product contains small parts that can cause a choking hazard if swallowed. Keep these parts away from children.
- Only use this product indoors. Using the product outdoors can lead to injuries and damage.
- **IMPORTANT:** Before installation, please check all components received against the components list. If parts are damaged or missing, ask your local dealer for replacement parts.

EU based economic operator ensuring the product complies with the required regulations.

www.digitus.com

info@assmann.com