

Quick change suction cup

SQC-C-RU-80x62-NBR

Part no.:10.01.18.01033

<https://www.schmalz.com/10.01.18.01033>

Homepage > Vacuum Clamping Technology > Clamping Equipment for Glass Processing > Quick-Change Systems for Bystronic Machines >

Schmalz Quick-Change SQC > SQC-C-RU-80x62-NBR



Quick Change Suction Cup



Shape: Round

Suction area: Diameter 80 mm


Material: Aluminium

Material workpiece support: Elastodur

Material hardness: 85 °Sh

Sealing material: Perbunan
for: Quick Change System

Design Data

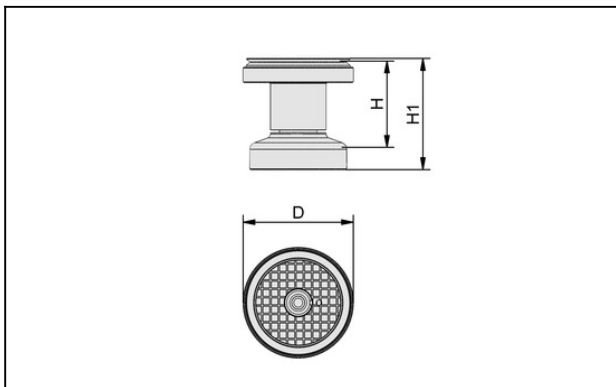

Attribute

Value

D	80 mm
H	62 mm
H1	79.8 mm

Spare Parts

Contact to Schmalz

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Quick change suction cup

SQC-C-RU-80x62-NBR

Part no.:10.01.18.01033

<https://www.schmalz.com/10.01.18.01033>



V-RING 63x11 V-070 NBR

Part no.10.07.08.00554

V-ring

Internal diameter d: 63 mm

Length L: 11 mm

Type: V-070

Material: Nitrile rubber NBR