


Keystone Module RJ45 jack > LSA Cat.6A UTP white

Description

This module by Delock can be used to connect twisted pair cable to an RJ45 jack. With its standardised dimensions it can be used for easy snap-in mounting in e.g. a Keystone patchpanel, face plate or surface-mount box.

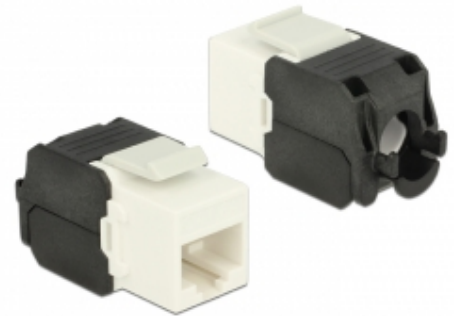

Item no. 86266

EAN: 4043619862665

Country of origin: China

Package: Zip poly bag


Technical details

- Connector: RJ45 jack (8P/8C) > LSA (tool-free)
- Unshielded (Cat.6A)
- Compliant with Cat.6_A requirements of ISO/IEC 11801 Edition 2.2, EN 50173-1:2011 and EN 60603-7-51, Cat.6A of ANSI/TIA 568-C.2
- TIA-568A/B pinout
- For solid or stranded wire up to 0.573 mm (23 - 26 AWG)
- Mounting with LSA-tool or tool-free
- For Keystone ports with 19.2 x 14.9 mm
- Colour: white
- Dimensions (LxWxH): ca. 37.8 x 16.0 x 22.5 mm

Package content

- Keystone module
- Two covers (depending on mounting)
- Zip-tie

Images

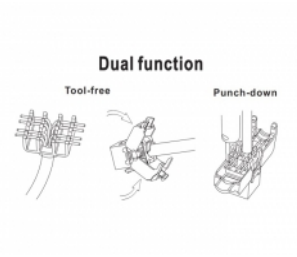

General

Mounting type:	Keystone module
Specification:	Cat. 6A

Interface

External:	1 x RJ45 jack
Internal:	1 x LSA block

Physical characteristics

Housing colour:	white
Housing material:	Plastic
Shielding:	unshielded
Length:	37.8 mm
Width:	16.0 mm
Height:	22.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

