

DIGITUS® CAT 6A Field Termination Coupler, 500 MHz

DN-93909

EAN 4016032431268



Field Termination Coupler CAT 6A, 500 MHz for AWG 22-26, fully shielded, keyst. design, 26x35x80

The DIGITUS Professional Field Termination Coupler is used for connecting or extending of twisted pair cables.

- Transmission properties: Category 6A, Class EA
- Area of application: Up to 500 MHz, 10GBase-T
- Suitable for cables with AWG 22-26 diameter
- Shell: Zinc alloy

- Contacts: Nickel-plated
- shielded
- Keystone Design
- 1 to 1
- Operating temperature: -10 °C to +60 °C

Attributes



- Category: CAT 6A

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	300	12.70	31.30	23.40	53.50	39,184.50
Packaging Unit Inside	30	1.27	8.00	3.50	2.60	72.80
Packaging Unit Single	1	0.04	9.00	8.00	3.00	216.00
Net single without Packaging	1	0.04	9.00	8.00	3.00	216.00

More images:



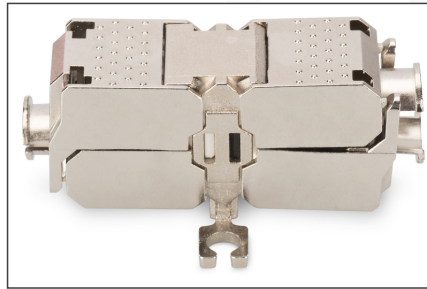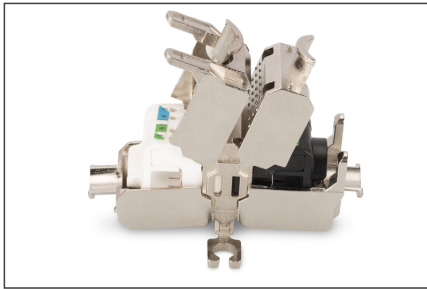

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com