



DVI(24+1) Male to HDMI Female Adapter

DVI to HDMI Adapter

Support resolution up to 1080P



Plug and Play

Lossless conversion

Dual transmission

Connect to DVI Monitors

Applicable to DVI (24+1) and DVI (24+5) monitors



Interface Display



DVI (24+1) male



Standard HDMI female

Dual Transmission

Support devices with DVI (24+1) and DVI (24+5) interface



Desktop



Laptop



Set-top box



Blu-ray machine



Game host



Projector



Monitor



TV



Standard HDMI



DVI-I(24+5)



DVI-D(24+1)



DVI(18+1)



1080P HD Visual Effect

Support 1920×1080 resolution, transmit digital signals



PS: The data is tested by the Vention laboratory

Fastening Nut Design

Strengthen the connection stability




Environmental PVC Shell

Meet RoHS environmental standards, more safety



Product Parameters

Brand: Vention	Version Type: HDMI 1.4
Name: DVI(24+1)to HDMI Adapter	Shell Material: PVC
Model: ECDB0	Resolution: 1080P
Appearance Color: Black	Transmission Direction: Dual directional
Interface Type: DVI(24+1) male, HDMI female	Product Warranty: One year
Interface Process: Gold plated	Package: PE bag

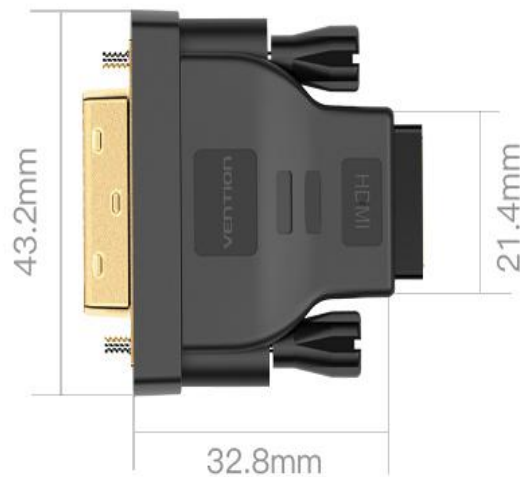

PS: Above marked size is hand dipping, maybe a slight tolerance there

Length	Art.No.	EAN Code
--------	---------	----------

ECDB0	6922794737945
-------	---------------

Package Contents

DVI to HDMI Adapter x 1

Packaging Information

Packing Dimension	mm
-------------------	----

Packing Weight	kg
----------------	----

Carton Dimension	48*29*30mm
------------------	------------

Carton Qty	500pcs
------------	--------

Carton Weight	12kg
---------------	------

Package	PE bag
---------	--------



www.ventioncable.com