


RJ45 Network Cable Cat.6A male to male S/FTP black 5 m with Cat.7 raw cable suitable for industrial and outdoor use

Description

This network cable by Delock can be used to connect different networking devices, e.g. a NIC to a switch or a patch panel.

For industrial and outdoor

The network cable is ideal for outdoor use and offers increased resistance to UV light, cold, heat, moisture and corrosion. It also has an increased bending strength, ideal for use in industrial areas.

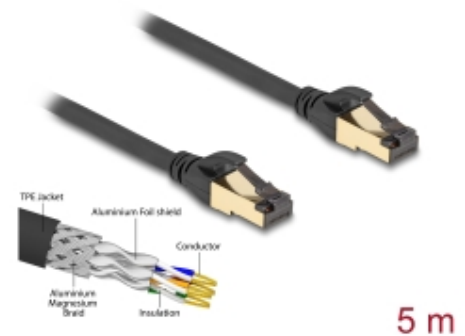

Item no. 80251

EAN: 4043619802517

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
1 x RJ45 plug Cat.6A
1 x RJ45 plug Cat.6A
- 1:1 connected
- Cat.7 specification
- Shielded (S/FTP)
- Bandwidth: 600 MHz
- Environmental temperature: -20 °C ~ 75 °C
- Cable gauge: 26 AWG
- Cable diameter: ca. 6.0 mm
- Cable jacket material: TPE
- Colour: black
- Length: ca. 5 m


System requirements

- A free RJ45 jack

Package content

- Patch cable

Images

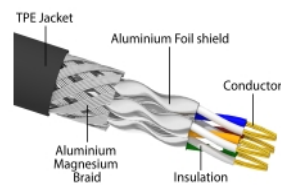

General

Specification:	Cat. 7
Style:	both sides identical

Interface

Connector 1:	1 x RJ45 male
Connector 2:	1 x RJ45 male

Technical characteristics

Operating temperature:	-20 °C ~ 75 °C
------------------------	----------------

Physical characteristics

Cable gauge:	26 AWG
Material:	TPE
Shielding:	S/FTP
Length:	5 m
Colour:	black
Cable diameter:	6 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de