


S/FTP Cat. 6A LSZH patch cord, green, 0.5 m

PP6A-LSZHCU-G-0.5M

- Perfect connection
- Dual shielded for a reliable connection
- Low Smoke Zero Halogen (LSZH) jacket
- Gold plated contacts

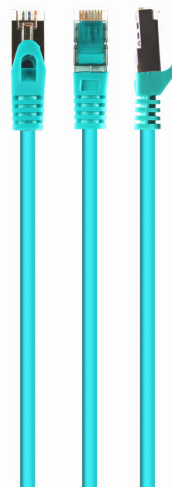

Specifications

Category: category 6A
 Type: SFTP (dual shielded)
 Frequency bandwidth: Max. 500 MHz
 Compliance with ANSI / TIA / EIA-568B standards
 Conductor: AWG 27 (7 x 0.135 mm wire), CU
 Conductor insulation: FM-PE 1.0 mm
 Shielding: AL foil + braid shield (16 x 4/0.12 mm)
 LDPE filler: yes
 Polyester tape: yes
 Drain wire: n/a
 Jacket material: LSZH
 Jacket braiding: n/a
 Jacket outer diameter: 6.2 mm
 Length: conform item description
 Color: conform item description

Features

- Patch cord with foil shielded pairs and braided cable, CAT 6A
- Gold plated contacts
- Low Smoke Zero Halogen (LSZH) jacket
- Molded strain reliefs
- Snagless boots

Packaging

Q'ty in crtn, pcs	300
Crtn volume, CUM	0.041
Crtn weight, kgs	8.42
Individual package size LxWxH:	150x120x10 mm
Carton size LxWxH:	400x300x340 mm
Country of origin	CN
Barcode	8716309091305
Customs code	8544421000

Certificates

