




Senso Dial ESD

Tough ESD matting for every environment



- Durable ESD mat for demanding workplaces with excellent all-round safety features.
- Soft foam backing provides exceptional fatigue-relief.
- Patterned rubber top surface provides grip in slippery situations.
- Ramped edges to reduce trips.
- Bespoke sizes and shapes available.
- Rp-p and Rg <math>< 1 \times 10^9 \Omega</math> tested per IEC 61340-4-1.
- Also available as a non-ESD anti-fatigue mat.

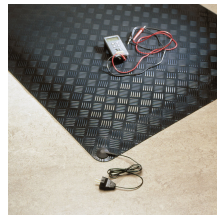

Parts

Part Number	Size	Colour	Weight (kg)
SN010010ESD	Special sizes available on request	Black	
SN010005ESD	1 m x 1.5 m	Black	8.25
SN010004ESD	0.6 m x 1 m	Black	3
SN010003CESD	1.2 m x per linear metre	Black	6.6
SN010003ESD	1.2 m x 10 m	Black	66
SN010002CESD	1 m x per linear metre	Black	4.6
SN010002ESD	1 m x 10 m	Black	46

Technical Specifications

Material	SBR/NBR top surface, EPDM foam base
Surface Finish	Deckplate pattern
Product Height	10 mm

Additional Information



Senso Dial ESD Test.jpeg

