


Technical data sheet

90° bend 60

Item no. 7001290

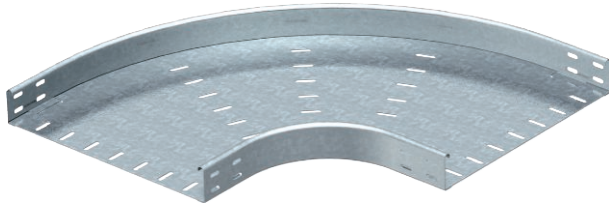

90° bend, horizontal, for all cable tray types of 60 mm side height.




St	Steel
FS	Strip galvanised

Additional product text, instruction	Fitting in round design. The interior radius of the fitting is 150 mm. Fastening materials should be ordered separately.
--------------------------------------	--

Master data

Item no.	7001290
Type	RB 90 640 FS
Description 1	90° bend
Description 2	horizontal, round type
Dimension	60x400
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	1,00 Piece
Weight	472,30 kg/100 pc.

Technical data

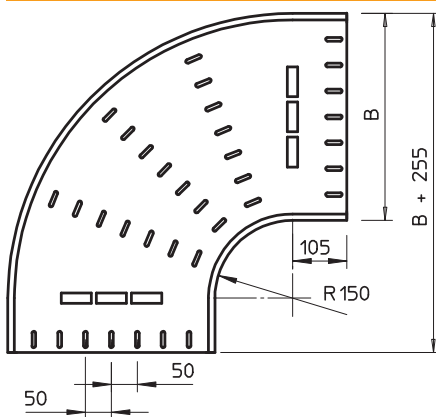

Width	400,00 mm
Side height	60,00 mm
Dimension B	400,00 mm
Dimension R	150,00 mm
Bend (angle)	90°
Connector version	Without connectors
Plate thickness	1,50 mm
Dimension	655 x 655 x 60 mm
Suitable for maintaining electrical function	☐
Mounting perforation in base	☐
NATO hole pattern	☐
Change of direction	Horizontal
Rustproof steel, pickled	☐
Side perforation	☐
Wide-span version	☐