

Keystone Module RJ45 jack to LSA Cat.6A toolfree shielded metal silver / white

Description

This module by Delock can be used to connect a network cable and is suitable for easy snap-in mounting in various holders, such as keystone patch panels, face plates or surface-mount boxes.



Item no. 90990

EAN: 4043619909902

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
 - 1 x RJ45 jack
 - 1 x LSA (toolfree)
- Cat.6A specification
- Shielded
- TIA-568A/B pinout
- For solid or stranded wire (26 - 22 AWG)
- For Keystone ports with 19.2 x 14.9 mm
- Operating temperature: -20 °C ~ 70 °C
- Material: zinc diecast
- Colour: silver / white
- Dimensions (LxWxH): ca. 34.5 x 16.2 x 20.0 mm

Package content

- Keystone module

Images

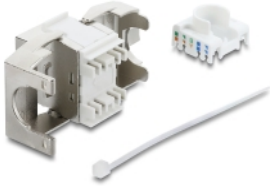

General

Specification:	Cat. 6A
----------------	---------

Interface

Connector 1:	1 x RJ45 jack
Connector 2:	1 x LSA (toolfree)

Technical characteristics

Operating temperature:	-20 °C ~ 70 °C
------------------------	----------------

Physical characteristics

Cable gauge:	26 - 22 AWG
Material:	zinc die cast
Shielding:	shielded
Length:	34.5 mm
Width:	16.2 mm
Height:	20 mm
Colour:	white silver

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

