


Fibre optic diffuse reflection sensor

FT-00-P-V-R1

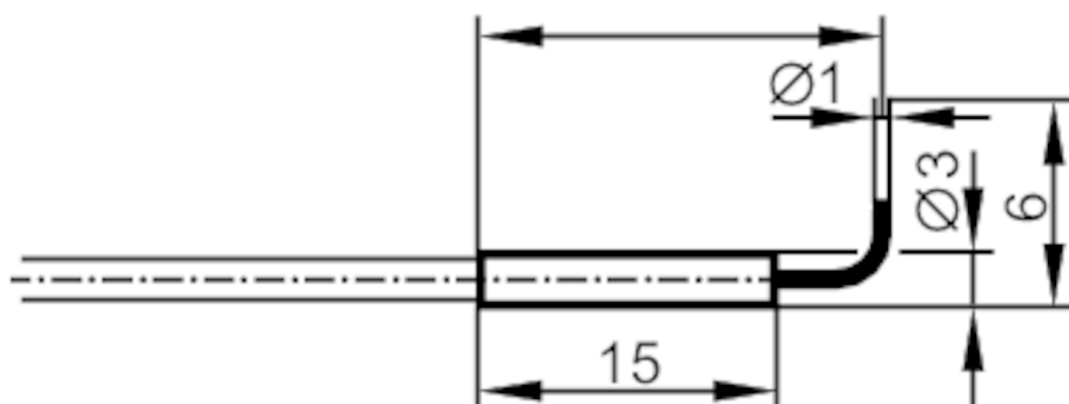

Application

Function principle	Diffuse reflection sensor
Application	For use in industrial environments

Detection zone

Range with fibre optic amplifier type	OCF; OKF; OOF; OUF
---------------------------------------	--------------------

OCF (High Power)

Range fibre optics	[mm]	40
--------------------	------	----

OKF

Range fibre optics	[mm]	6
--------------------	------	---

OOF

Range fibre optics	[mm]	24
--------------------	------	----

OUF

Range fibre optics	[mm]	6
--------------------	------	---

Operating conditions

Ambient temperature	[°C]	-20...80
---------------------	------	----------

Mechanical data

Weight	[g]	37
Version of sensing head		angled
Sensing head diameter	[mm]	1

E20230



Fibre optic diffuse reflection sensor

FT-00-P-V-R1

Total length	[mm]	600
Min. bending radius	[mm]	20
Fibre arrangement		①
Fibre material		glass
Fibre head material		stainless steel (304/1.4301)
Fibre sheath material		PVC
Accessories		
Items supplied		Mounting clamp:, E20107
Remarks		
Pack quantity		1 pcs.