


Cable Optical Fibre LC-APC to LC-APC Simplex Singlemode OS2 0.5 m

Description

This fibre optic cable by Delock can be used to connect various network devices, e.g. an FTTH house interconnection point with a fibre optic modem.

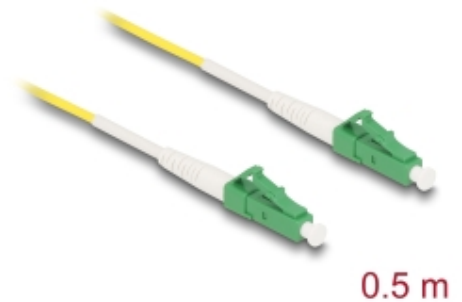

Item no. 83219

EAN: 4043619832194

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
1 x LC-APC Simplex
1 x LC-APC Simplex
- APC 8°
- Ceramic ferrule with dust protection
- Singlemode OS2 cable G657.A2
- Fibre: 9/125 µm
- Return loss: 60 dB
- Smallest bending radius: 7.5 mm
- Cable diameter: ca. 2.0 mm
- LSOH (halogen-free)
- Operating temperature: -20 °C ~ 70 °C
- Colour: yellow
- Cable length: ca. 0.5 m

Package content

- Optical fiber cable

Images



General

Specification:	OS2
Style:	both sides identical

Interface

Connector 1:	1 x LC Simplex male
Connector 2:	1 x LC Simplex male

Technical characteristics

Operating temperature:	-20 °C ~ 70 °C
------------------------	----------------

Physical characteristics

Cable colour:	yellow
Cable length incl. connectors:	0.5 m
Smallest bending radius:	7.5 mm
Cable diameter:	2 mm
Cable jacket material:	LSOH (halogen-free)

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

