

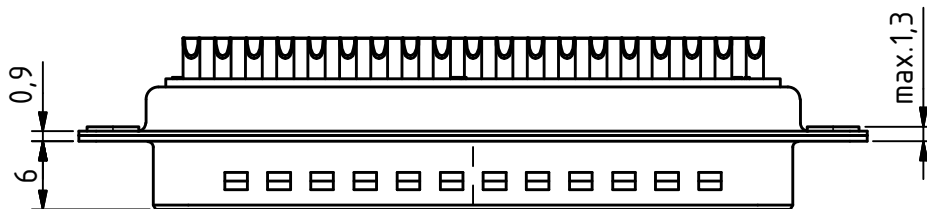
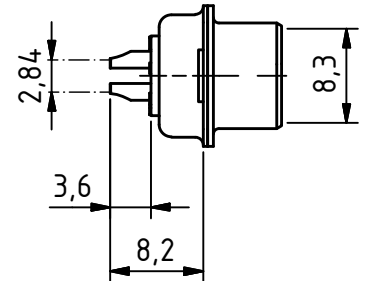


RoHS compliant

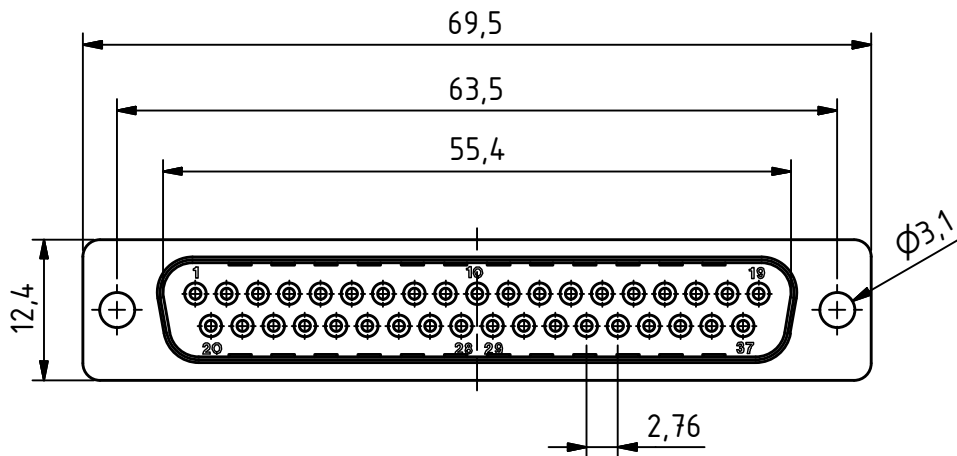

suitable for cable AWG 18 (single solid wire)

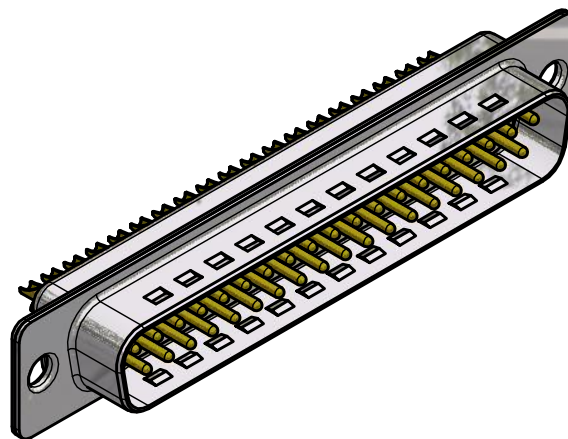

 
MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm				
> 0.5	> 3	> 6	> 30	
up to 3	up to 6	up to 30	up to 120	
tolerances				
±0.1	±0.2	±0.2	±0.3	

	All dimensions in mm	Rev. a) 17.04.1998 mr	Rev.	Rev.	DE001229		
		Rev.	Rev.	Rev.	part no.		
DTS37PZ/2				1.5:1 scale	drawn	25.11.1996	mr
					checked		
					approved		
				K050015 a			
Industrie NeuhoF 8c CH-3422 Kirchberg www.d-sub.swiss				drawing no.			