

Quick change suction cup

SQC-C-RU-80x102-NBR

Part no.:10.01.18.01037

<https://www.schmalz.com/10.01.18.01037>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Glass Processing > Quick-Change Systems for Bystronic Machines >

Schmalz Quick-Change SQC > SQC-C-RU-80x102-NBR

Quick Change Suction Cup



Shape: Round

Suction area: Diameter 80 mm


Material: Aluminium

Material workpiece support: Elastodur

Material hardness: 85 °Sh

Sealing material: Perbunan
for: Quick Change System

Design Data

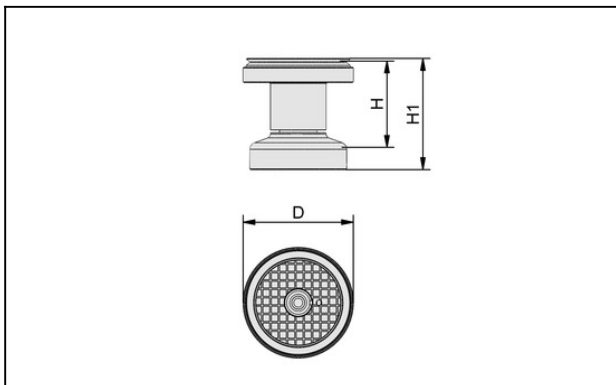

Attribute

Value

D	80 mm
H	102 mm
H1	119.8 mm

Spare Parts

Quick change suction cup

SQC-C-RU-80x102-NBR

Part no.:10.01.18.01037

<https://www.schmalz.com/10.01.18.01037>



V-RING 63x11 V-070 NBR

Part no.10.07.08.00554

V-ring

Internal diameter d: 63 mm

Length L: 11 mm

Type: V-070

Material: Nitrile rubber NBR