

Delock Antenna Base SMA plug > SMA Jack 1 m Black Low Loss

Description

This practical antenna base can be used universally in following applications:

1. wall mounted
2. upright on the table
3. on metallic surfaces magnetically adhering.



1 m

Item no. 88973

EAN: 4043619889730

Country of origin: Taiwan,
Republic of China

Package: Zip poly bag


Technical details

- Connector:
Base: SMA jack
Cable: SMA plug
- Cable length: 1 m
- Cable type: ULA100 low loss
- Cable attenuation: 2.400 ~ 2.500 GHz: 1.40 dB
4.900 ~ 5.875 GHz: 2.30 dB
- Operating temperature: -10°C ~ 55°C
- ABS UV resistant
- Dimension (LxWxH): 80.0 x 77.1 x 22.5 mm
- Diameter SMA plug: 8 ~ 9 mm

Package content

- Antenna base

Images

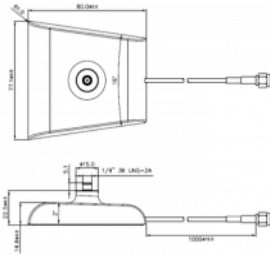

General

Mounting type:	magnetic
----------------	----------

Interface

Connector 1:	1 x SMA jack
Connector 2:	1 x SMA plug

Technical characteristics

Operating temperature:	-10 °C ~ 55 °C
------------------------	----------------

Physical characteristics

Housing material:	ABS UV resistant
Cable type:	ULA 100 low loss
Cable length:	1 m
Length:	80.0 mm
Width:	77.1 mm
Height:	22.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

