

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



Homepage > Vacuum Technology for Automation > Vacuum Components > Filters and Connections > Hoses and Connectors > Vacuum /


Compressed Air Hoses VSL > VSL 12-9 PU

Hose for vacuum and compressed-air systems



External diameter D: 12 mm
Internal diameter d: 9 mm
Length (max): 50 m
Material: PU
Installation radius (min): 70 mm
Pressure range (operating pressure):
-0.95 ... 10.00 bar
Ambient temperature: -20 ... 90 °C

Design Data

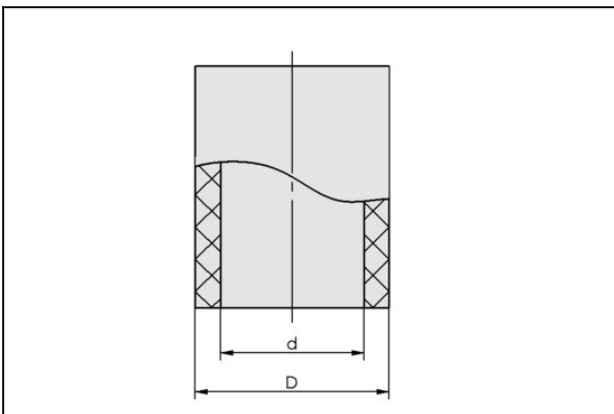

Attribute	Value
d	9 mm
D	12 mm

Technical Data

Attribute	Value
Hose type	12-9
Pressure range (operating pressure)	-0,95 ... 10,00 bar
Operating temperature	-20 ... 90 °C

Contact to Schmalz

Schmalz Sp.z.o.o. | Kobaltowa 4, 62-002 Złotniki, Polen | +48 22 460 49 70 | schmalz@schmalz.pl

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



Attribute	Value
Bending radius min.	70 mm
Length max.	50 m
Weight/Meter	58 g/m
Weight/Meter	0.058 kg/m
Material hose	PU

Note: Operating pressure: In reference to media and ambient temperature of + 20°C Bending radius: Referred to the inner side of the hose bend in a static state Max. length: Please indicate the tube length when placing the order!

Accessories




SSB 10-16 ST-VZ

Part no.10.07.10.00001

Hose clamp for securing smooth hoses

Clamping range: 10.0 ... 16.0 mm

Material: Steel galvanised

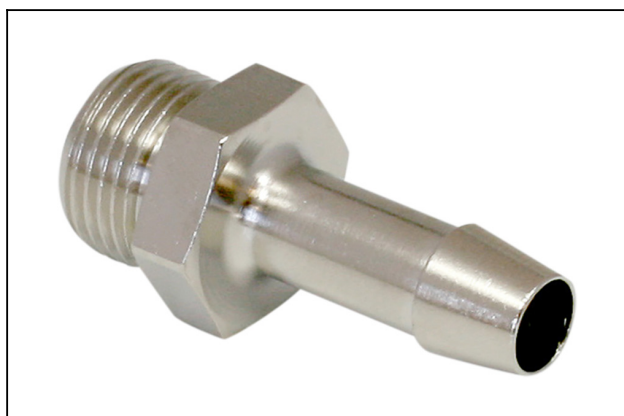

ST G1/2-AG 9 MS-V

Part no.10.08.03.00161

Hose sleeve

Thread G1: G1/2"-M

Internal hose diameter: 9 mm

Material: Brass

Surface: nickel plated

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



ST G1/4-AG 9 MS-V

Part no.10.08.03.00157

Hose sleeve

Thread G1: G1/4"-M

Internal hose diameter: 9 mm

Material: Brass

Surface: nickel plated



ST G1/8-AG 9 MS-V

Part no.10.08.03.00155


Hose sleeve

Thread G1: G1/8"-M

Internal hose diameter: 9 mm

Material: Brass

Surface: nickel plated

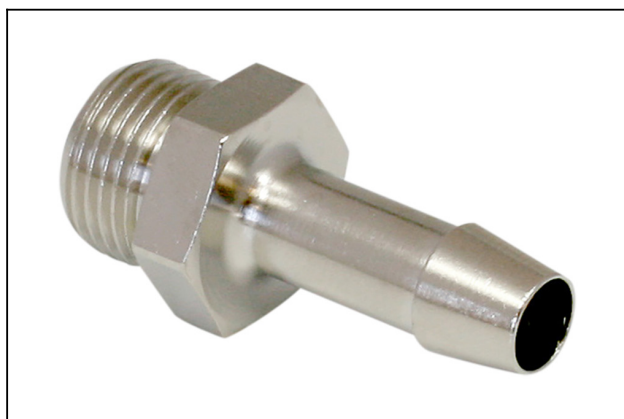

ST G3/8-AG 9 MS-V

Part no.10.08.03.00159

Hose sleeve

Thread G1: G3/8"-M

Internal hose diameter: 9 mm

Material: Brass

Surface: nickel plated

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



STV-GE G1/2-AG 12

Part no.10.08.02.00210

Push-in Fitting, straight

Thread G1: G1/2"-M

External hose diameter: 12 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C



STV-GE G1/4-AG 12

Part no.10.08.02.00208

Push-in Fitting, straight

Thread G1: G1/4"-M

External hose diameter: 12 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C



STV-GE G3/8-AG 12

Part no.10.08.02.00209

Push-in Fitting, straight

Thread G1: G3/8"-M

External hose diameter: 12 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



STV-T G1/4-AG 12

Part no.10.09.02.00045

Push-in Fitting, T

Thread G1: G1/4"-M

External hose diameter: 12 mm

Length L: 69 mm

Material: Brass

Surface: nickel plated



STV-W G1/2-AG 12

Part no.10.08.02.00164

Push-in Fitting, swivelling elbow

Thread G1: G1/2"-M

External hose diameter: 12 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



STV-W G1/4-AG 12

Part no.10.08.02.00162

Push-in Fitting, swivelling elbow

Thread G1: G1/4"-M

External hose diameter: 12 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C

Vacuum hose

VSL 12-9 PU

Part no.:10.07.09.00037

<https://www.schmalz.com/10.07.09.00037>



STV-W G3/8-AG 12

Part no.10.08.02.00163

Push-in Fitting, swivelling elbow

Thread G1: G3/8"-M

External hose diameter: 12 mm

Material: Brass, nickel-plated

Ambient temperature: -20 ... 80 °C



SVB-T 12

Part no.10.09.02.00023

Plug connection, T

External hose diameter: 12 mm

Length L: 69 mm

Material: Brass

Surface: nickel plated

Ambient temperature: -20 ... 80 °C