 





Orthomat® Diamond Anti Fatigue Mat

Diamond pattern anti-fatigue mat for dry workplaces



- Versatile single layer foam anti-fatigue mat.
- Insulates standing workers against the effects of cold concrete floors.
- Lightweight, so easy to transport and reposition.
- Best suited to dry environments.
- High visibility version available with bright yellow borders.
- Ideal for lighter industrial use.
- Industrial-look diamond surface pattern.
- Available in mats and rolls.
- Fire tested to BS EN 13501-1.

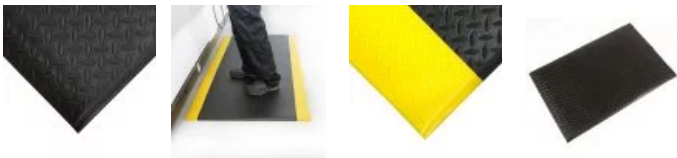

Parts

Part Number	Size	Colour	Weight
DAF010001	0.6 m x 0.9 m	Black	1.50 kg
DAF010002	0.9 m x 1.5 m	Black	3.00 kg
DAF010003	0.9 m x 18.3 m	Black	38.00 kg
DAF010003C	0.9 m x per linear metre	Black	2.00 kg
DAF010005	1.2 m x 18.3 m	Black	51.00 kg
DAF010005C	1.2 m x per linear metre	Black	4.00 kg
DAF010701	0.6 m x 0.9 m	Black/Yellow	1.50 kg
DAF010702	0.9 m x 1.5 m	Black/Yellow	3.00 kg
DAF010703	0.9 m x 18.3 m	Black/Yellow	38.00 kg
DAF010703C	0.9 m per linear metre	Black/Yellow	2.00 kg
DAF010705	1.2 m x 18.3 m	Black/Yellow	51.00 kg
DAF010705C	1.2 m x per linear metre	Black/Yellow	4.00 kg

Technical Specification

Material	Open Cell PVC (Foam)
Surface Finish	Diamond pattern
Product Height	9.5 mm
Size of Safety Border	100 mm
Operating Temperature	0°C to +60°C
Environmental Resistance	Suitable for dry indoor environments
Typical Applications	Production lines, Assembly areas, Packing stations, Workbenches
Installation Method	Loose lay
Cleaning Method	Brush/mop the top surface
Fire Tested to	BS EN 13501-1 Class Dfl - s1
Country of Origin	China
Guarantee	1 year when used in a dry environment
Adhesive recommended by F.Ball for permanent bond	F44
Tackifier recommended by F.Ball	F41
Adhesive recommended by	F74, F81, F84

