

Quick change Mono Base

SQC-MB-62.9x18-M12-AG

Part no.:10.01.18.01031

<https://www.schmalz.com/10.01.18.01031>



Homepage > Vacuum Clamping Technology > Clamping Equipment for Glass Processing > Quick-Change Systems for Bystronic Machines >

Schmalz Quick-Change SQC > SQC-MB-62.9x18-M12-AG

Quick change Mono Base for automated clamping




External diameter D: 62.9 mm

Height H: 18 mm

Thread G1: M12-M

for: Quick Change System

Design Data

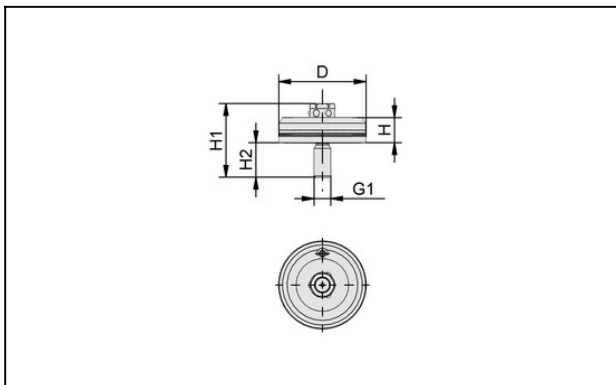

Attribute

Value

D	62.9 mm
---	---------

G1	M12-AG
----	--------

H	18 mm
---	-------

H1	52.8 mm
----	---------

H2	24.8 mm
----	---------

 
Spare Parts

Quick change Mono Base

SQC-MB-62.9x18-M12-AG

Part no.:10.01.18.01031

<https://www.schmalz.com/10.01.18.01031>



SCHR M12x52.9 VC-SYS

 
Part no.10.01.18.01030

Hollow screw, special shape

Thread G: M12

Length L: 52.9 mm

for: Vacuum clamping system



DRUC-STK 2.4x14 M5-AG GN615.1

Part no.20.05.07.00137

Pressure piece

External diameter D: 2.4 mm

Length L: 14 mm

Thread G1: M5-M

Type: GN615.1