




DIN 85 A

~ISO 1580

4.8

Norme abrogée

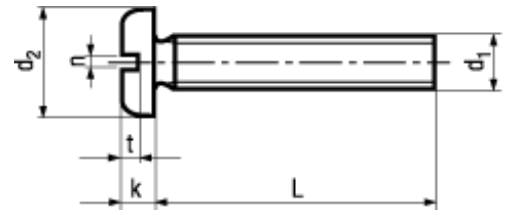

## BN 346


## Vis à tête aplatie Pan-Head

à fente

Acier 4.8

zingué-jaune

- ~UNI 6108
- ~ČSN 021137

 [3D Cadenas](#)
 Toutes les longueurs avec filetage ~ sous tête

M2,5: selon ISO 1580

Article#	d <sub>1</sub>	d <sub>2</sub>	k max.	n	t min.	L
1132229	M2,5	5	1,5	0,6	0,6	5
1132237						6
1132245						8
1132253						10
1132261						12
1132296						16
1132504	M3	6	1,8	0,8	0,7	4
1132512						5
1132520						6
1132539						8
1132547						10
1132555						12
1132563						(14)
1132571						16
1132601						20
1132644						30
1132660						40
3056160	M4	8	2,4	1,2	1	5
1132857						6
1132865						8
1132873						10
1132881						12
1132911						16
1132946						20
1132962						25
3056161	M5	10	3	1,2	1,2	6

Article#	d <sub>1</sub>	d <sub>2</sub>	k max.	n	t min.	L
1133039	M5	10	3	1,2	1,2	8
1133047						10
1133055						12
1133063						(14)
1133071						16
1133101						20
1133195	M6	12	3,6	1,6	1,4	8
1133209						10
1133217						12
1133233						16
1133268						20
1133284						25
1133292						30
1133306						35