

USB 2.0 extension cable EASY USB Type-A male to EASY USB Type-A female 0.2 m

Description

This cable by Delock allows the extension of a USB connection and can be used to connect various devices. The cable is used both for data transmission and for power supply of the connected device.

User-friendly reversible EASY USB connectors

Both the EASY USB male and the EASY USB female connector are twist-proof and can be used on both sides, so there is no need to pay attention to the correct top or bottom side when inserting a plug.



0.2 m

Item no. 81510

EAN: 4043619815104

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
 - 1 x USB 2.0 Type-A reversible male
 - 1 x USB 2.0 Type-A reversible female
- USB Type-A male usable in both directions
- USB Type-A female usable in both directions
- Cable gauge:
 - 28 AWG data line
 - 24 AWG power line
- Cable diameter: ca. 4.5 mm
- Gold-plated connector
- Cable double shielded
- Data transfer rate up to 480 Mbps
- Colour: black
- Length incl. connectors: ca. 0.2 m

Package content

- USB cable

Images

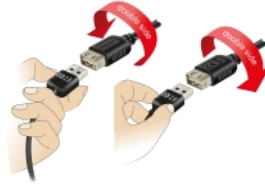

General

Style:	EASY-USB
--------	----------

Interface

Connector 1:	1 x EASY-USB 2.0 Type-A male
Connector 2:	1 x EASY-USB 2.0 Type-A female

Technical characteristics

Data transfer rate:	480 Mbps
---------------------	----------

Physical characteristics

Pin finishing:	gold-plated
Cable gauge:	28 AWG data line 24 AWG power line
Shielding:	double
Length:	0.2 m
Colour:	black
Cable diameter:	4.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de