

Type BLR-912-G

Fuse Block

12 Pole - Regular, ATC/ATO Auto Blade

With 12-Position Grounding Block



www.optifuse.com

(619) 593-5050

Specifications:

Max Voltage: 32VDC

Max Current Rating: 30A per Circuit - 100A Max

Fuse Type: Regular, ATO / ATC, Auto Blade (APR / ANR series)
(Fuses or Circuit Breakers)

Mounting: 4 mounting holes, 4.5mm diameter

Indicating LED – Red

Temperature Rating: -20° C ~ +85° C


Material:

Housing & Base: PBT, Black

Cover: PC, Clear

Terminals: Copper

Mechanical Dimensions: Inches [mm]

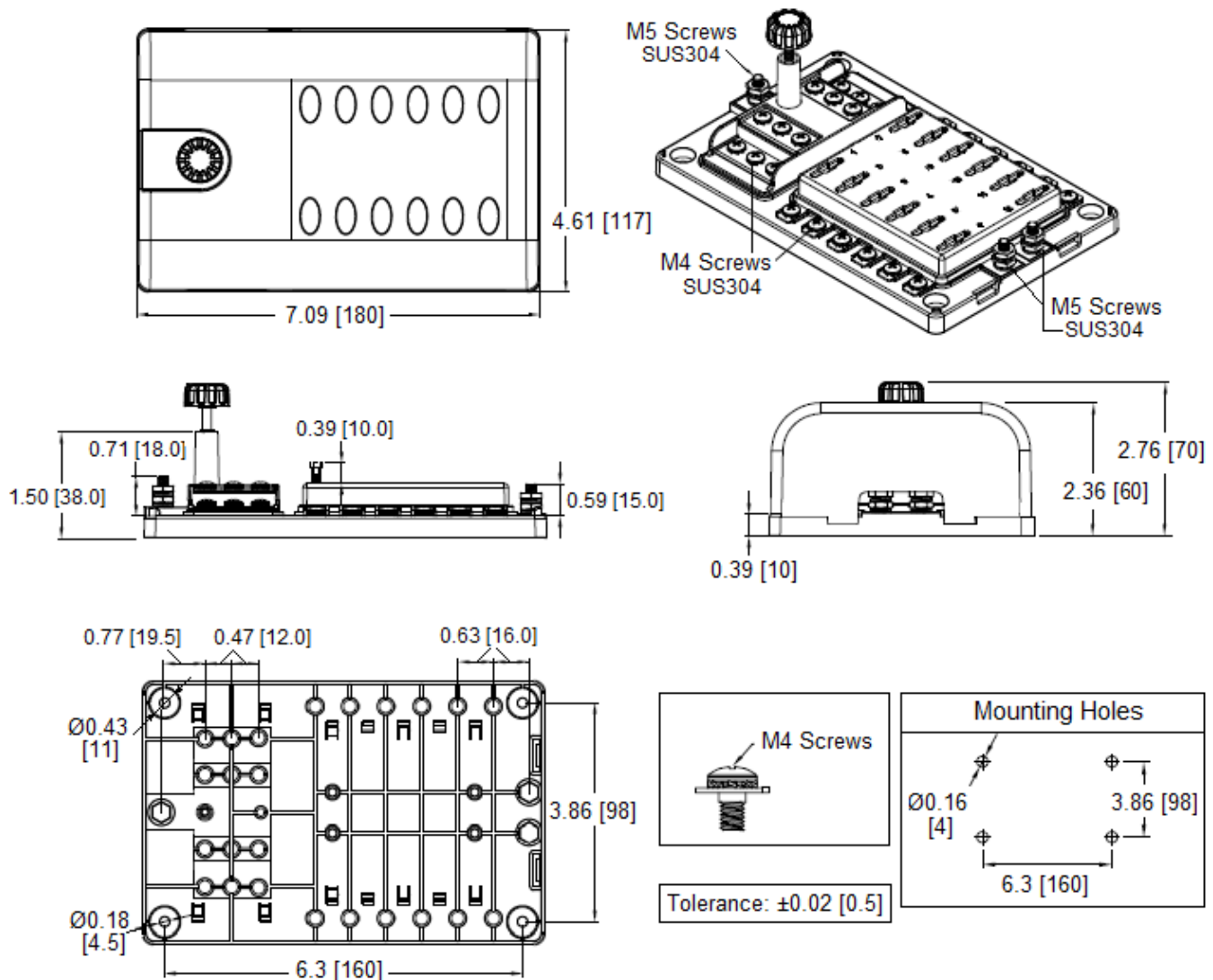

Warning:



-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.

-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.

Note: All specifications subject to change without notice.

Rev A 08/2018 - Page: 1/1
Code S02-01H