

# LogiLink®



## 4K HDMI Splitter, 1x2 Ports 4K/60 Hz, EDID, Downscaler

Art. No.: HD0066


This 4K HDMI Splitter with EDID management is an advanced solution for splitting a single HDMI input to two HDMI outputs. It provides high performance audio and video output up to Ultra HD 4K@60 Hz resolution and delivers up to 18 Gbps of bandwidth, ensuring the best 4K picture quality.

### Features:

- » Connects one HDMI source to two HDMI displays at the same time
- » Resolution up to UHD 4K@60 Hz (YUV 4:4:4) and Full 3D
- » Bandwidth up to 18 Gbps (6 Gbps at 600 MHz per channel)
- » Compliant with HDCP 2.2 and EDID management
- » Supports 36 bit Deep Color (12 bit per channel)
- » Supports DDC, HDR, CEC and downscaler function
- » Supports LPCM 7.1, Dolby TrueHD and DTS-HD Master Audio™
- » Power through USB cable



- (a) Power LED
- (b) HDMI output 1 & 2 LED indicator
- (c) Auto mode LED
- (d) Copy mode LED
- (e) Downscaler mode LED
- (f) EDID button
- (g) USB-C port for power input (DC 5 V)
- (h) HDMI input
- (i) HDMI output 1 & 2

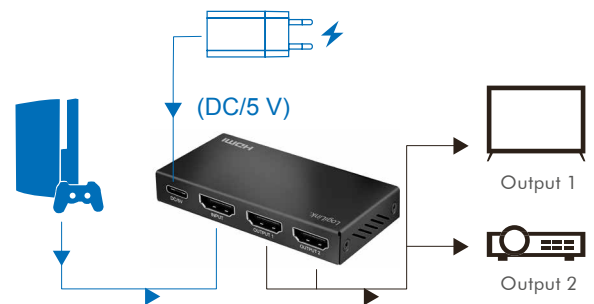

The „Downscaler“ function allows the product to display the 4K input resolution on two screens/monitors with different maximum resolutions (e.g. 1080p and 4K) simultaneously. This is useful, for example, when using an older Full HD (1080p) monitor and a newer Ultra HD (4K) monitor at the same time.

## Specifications:

Input Port	1x HDMI-A female, 1x USB-C female
Output Ports	2x HDMI-A female
HDMI Standard	2.0
HDCP Version	2.2
Output Resolution	480i/60 Hz, 576i/50 Hz, 1080i/50/60 Hz, 480p/60 Hz, 576p/50 Hz, 720p/50/60 Hz, 1080p/24/25/30/50/60 Hz, 4K@24/25/30 Hz, 4K@50/60 Hz 4:4:4
Video Bandwidth	Up to 18 Gbps
EDID Management	Yes (copy and downscaler)
CEC (Consumer Electronics Control)	Yes
HDR (High-Dynamic Range)	Yes
DDC (Display Data Channel)	Yes
TMDS (Transition Minimized Differential Signaling)	Yes
LED Indicator	Yes
3D Supporting	Yes
Chassis Material	Metal
Power By	Charge thru USB-C port (DC 5 V/1 A, 5 W)
Uncompressed Audio	LPCM 7.1
Compressed Audio	DTS, Dolby Digital, DTS-HD Master Audio, Dolby TrueHD
Operating Temperature	0–70°C
Operating Humidity	10–85% RH (no condensation)
Dimensions	9 x 4.4 x 1.4 cm
Weight	0.093 g
Cable Length	75 cm
Color	Black

## Package Contents:

- » 1x HDMI Splitter
- » 1x USB Charging Cable
- » 1x User Manual

## Package Information:

- » Packing Dimension: 167 x 110 x 52 mm
- » Packing Weight: 0.198 kg
- » Carton Dimension: 575 x 255 x 360 mm
- » Carton Q'ty: 40 pcs
- » Carton Weight: 8.5 kg



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



HD0066



4 052792 078978

Made in China