

USB Type-C™ Splitter (DP Alt Mode) to 3 x DisplayPort MST 4K 60 Hz

Description

This splitter by Delock is suitable for the connection of **three DisplayPort monitors** to a computer with **USB-C™** interface and DisplayPort alternate mode support. Three monitors can be operated simultaneously at the outputs.

Multi-Stream Transport (MST)

The product is a Multi-Stream Transport (MST) hub and supports the extended desktop configuration of DisplayPort. In Windows, the connected monitors are controlled individually, and can be combined into one large display.

High resolution

Due to the higher bandwidth of DisplayPort 1.4, a total of three monitors with 4K resolution (3840 x 2160) are supported.



Item no. 88041

EAN: 4043619880416

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - Input: 1 x USB Type-C™ male
 - Output: 3 x DisplayPort female
- Chipset: VMM5330
- DisplayPort 1.4 specification
- Active converter, Single- / Multi-Stream Transport Hub (SST / MST)
- Supports HDR
- Supports HDCP 1.4 and 2.2
- Supports Display Stream Compression 1.2 (DSC)
- Maximum resolution (depending on the system and the connected hardware):
 - DisplayPort 1.4 Multi-Stream Transport (MST):
 - 2 displays: up to 3840 x 2160 @ 60 Hz
 - 3 displays: 2 x up to 3840 x 2160 @ 30 Hz + 1 x up to 3840 x 2160 @ 60 Hz
 - DisplayPort 1.4 Multi-Stream Transport (MST) + DSC:
 - 3 displays: up to 3840 x 2160 @ 60 Hz
- Functions: Mirrored or Extended (Windows only)
- Transmission of audio and video signals
- USB bus powered
- Colour: black
- Cable length without connectors: ca. 15 cm
- Dimensions without cable (LxWxH): ca. 87 x 36 x 12 mm


System requirements

- Windows 10/10-64/11
- PC or laptop with a free USB Type-C™ port and DisplayPort alternate mode or
- PC or laptop with a free Thunderbolt™ 3 port

Package content

- USB-C™ Splitter (DP Alt Mode)
- User manual

Images

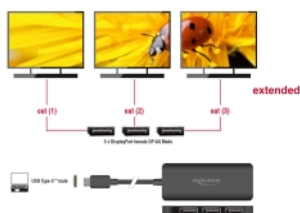

General

Specification:	DisplayPort 1.4
Supported operating system:	Windows 10 32-Bit Windows 10 64-Bit Windows 11

Interface

Output:	3 x DisplayPort female
Input:	1 x USB Type-C™ male

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 60 Hz
----------------------------	---------------------

Physical characteristics

Housing colour:	black
Cable length:	15 cm
Length:	87 mm
Width:	36 mm
Height:	12 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de