
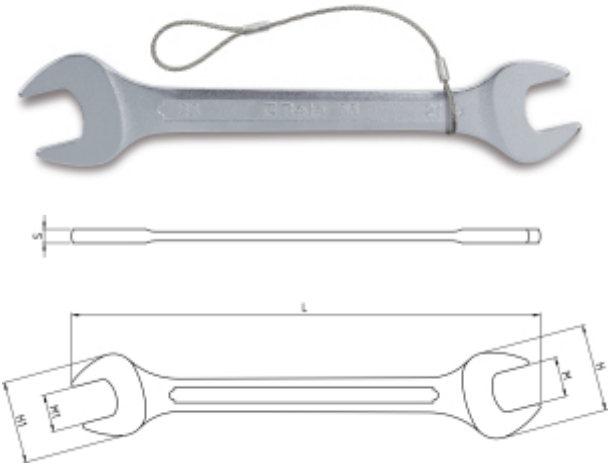


UNI-ISO 10102 DIN 3110

with H-SAFE tethered system

		Art.	M mm	M1 mm	L mm	H mm	H1 mm	S mm	g
•	000554012	55HS 6X7	7	6	120	17,5	15,5	3,5	21
•	000554021	55HS 8X9	9	8	140	21,5	19,5	4	34
•	000554030	55HS 10X11	11	10	155	25,5	23,5	4,5	47
•	000554042	55HS 12X13	13	12	170	29,5	27,5	5	69
•	000554054	55HS 14X15	15	14	185	33,5	31,5	5,5	92
•	000554060	55HS 16X17	17	16	202	37,5	35,5	6	122
•	000554066	55HS 18X19	19	18	220	41,5	39,5	6,5	134
•	000554075	55HS 20X22	22	20	236	47,5	43,5	7	207
•	000554078	55HS 21X23	23	21	245	49,5	45,5	7,6	245
•	000554081	55HS 22X24	24	22	245	49,5	45,5	7,6	233
•	000554090	55HS 24X27	27	24	262	55,5	51,5	8	310
•	000554108	55HS 30X32	32	30	297	67,5	63,5	9	490
•	000554117	55HS 34X36	36	34	325	76,1	68,4	11	614



Scan the QR Code to access the web tab
 Specs, media and documentation in one click.

