


Plugs

MST 3

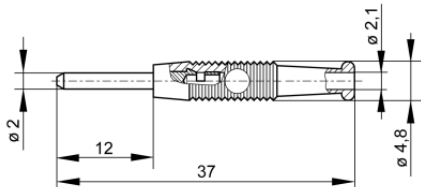

Product	MST 3
description	2 mm diameter miniature connector, nickel-plated brass pin with solder connection. Flexible, shatter-proof insulated sleeve. For making up connecting leads with a maximum external diameter of 1.9 mm.
operating instruction	BA207
article-no. / *colour	9735091xx  00 black  01 red  02 blue  03 yellow  04 green  06 gray Ni
drawing	
	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material plug	brass, nickel plated
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +60 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022

2 mm system