

3 Port USB 5 Gbps Hub + RJ45 Gigabit LAN PoE++ Port with USB Type-C™ host-connector in metal case and 1.5 kV Isolation

Description

This solid USB hub by Delock with **metal housing** can be connected to a computer, laptop or mobile device via the USB-C™ interface. Up to **3 USB devices** can be connected to the hub.

Integrated 10/100/1000 Mbps LAN PoE++ interface

In addition, the hub with integrated **RJ45 Gigabit LAN** connection expands a PC or laptop by a network interface.

The port also serves to power a device connected to the hub. Up to **60 W** can be made available **for the host device**. Thus, the host device can be used continuously when a power source is available at the network port.

Electrical protection

The hub has a built-in DC/DC converter that supports a wide input voltage range. All outputs have overvoltage protection, short circuit protection and overtemperature protection, as well as **1500 V electrical isolation**.



Item no. 64336

EAN: 4043619643363

Country of origin: China

Package: Box

Technical details

- Connectors:
 - 1 x USB 5 Gbps USB Type-C™ female
 - 3 x USB 5 Gbps Type-A female
 - 1 x Gigabit LAN RJ45 jack
- Chipset: VIA VL817, Realtek RTL8153
- Data transfer rate:
 - Ethernet up to 10 Mbps (Half/Full Duplex)
 - Fast Ethernet up to 100 Mbps (Half/Full Duplex)
 - Gigabit Ethernet up to 1000 Mbps (Half/Full Duplex)
- Compatible with:
 - IEEE 802.3: 10BASE-T
 - IEEE 802.3u: 100BASE-TX
 - IEEE 802.3ab: 1000BASE-T
- Supports Auto MDI-X (automatic detection of standard or crossover network cable)
- Supports Wake On LAN (WOL)
- Supports IEEE 802.3az (Energy Efficient Ethernet)
- Supports IEEE 802.1Q Virtual LAN (VLAN)

- Support full duplex operation with IEEE 802.3x flow control and half duplex operation with back-pressure
- Supports IEEE 802.3at PoE+
- Supports IEEE 802.3bt PoE++
- Supports 4k Jumbo Frames
- Output power for host: max. 60 W
- 1.5 kV input and output isolation
- Surge Protection
- Short circuit protection
- Overheating protection
- Robust metal housing
- Dimensions (LxWxH): ca. 127 x 68 x 28 mm
- Colour: black
- Plug & Play


System requirements

- Android 14.0 or above
- Chrome OS
- Linux Kernel 6.5 or above
- Mac OS 14.5 or above
- Windows 10/10-64/11
- iPad Air (4th Generation) or above
- iPad Pro (3rd Generation) or above
- Surface Pro 7
- Device with a free USB Type-C™ port or with a free Thunderbolt™ 3 or Thunderbolt™ 4 port

Package content

- USB hub + LAN
- Cable USB-C™ male to USB-C™ male, length ca. 60 cm
- Mounting material
- User manual

Images

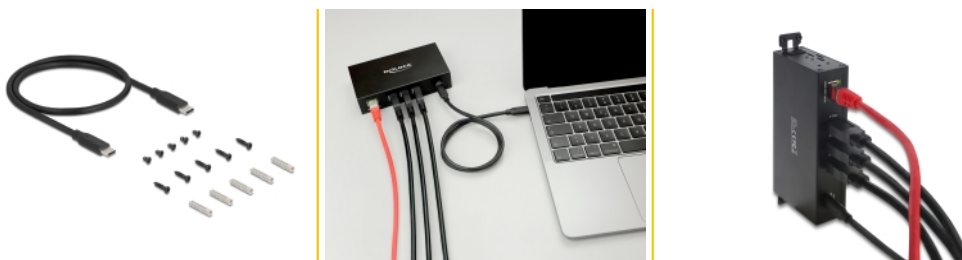

General

Function:	Plug & Play
Supported operating system:	Chrome OS Surface Pro 7 Windows 10 32-Bit Windows 10 64-Bit iPad Pro (3rd Generation) or above iPad Air (4th Generation) or above Windows 11 Android 14.0 or above Linux Kernel 6.5 or above Mac OS 14.5 or above

Interface

Connector 1:	1 x USB 5 Gbps USB Type-C™ female
Connector 2:	3 x USB 5 Gbps Type-A female
Connector 3:	1 x Gigabit LAN RJ45 jack

Technical characteristics

Chipset:	Realtek RTL8153 VIA VL817
Data transfer rate:	Ethernet up to 10 Mbps Fast Ethernet up to 100 Mbps Gigabit Ethernet up to 1000 Mbps

Physical characteristics

Housing material:	metal
Length:	127 mm
Width:	68 mm
Height:	28 mm
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

