


Optical Fiber Hybrid Coupler LC Simplex female to ST Simplex female beige

Description

This LC Simplex to ST Simplex hybrid coupling by Delock enables the conversion from one connector type to the other. This means that LC and ST optical fiber cables can be easily connected to each other and they are suitable for mounting in optical fiber connection boxes, cabinets and patch panels.

Protection by dust cover

The coupling is equipped with an appropriate cap to protect the sleeve from dust and to keep it clean.

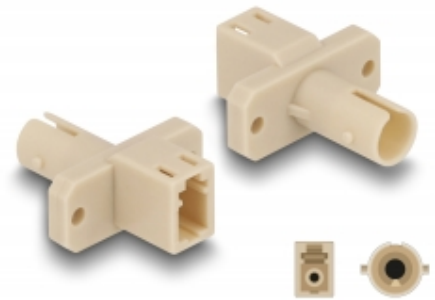

Item no. 87939

EAN: 4043619879397

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
1 x LC Simplex female
1 x ST Simplex female
- Return loss: 50 dB
- Material: ceramic
- Ceramic sleeve
- With dust cover
- Mounting with screws
- 2 x mounting holes
- Mounting hole diameter: ca. 2.3 mm
- Pitch of screw hole: ca. 18 mm
- Operating temperature: -40 °C ~ 80 °C
- Colour: beige
- Material: plastic
- Dimensions (LxWxH): ca. 26.0 x 22.0 x 9.3 mm


System requirements

- A free LC Simplex male port
- A free ST Simplex male port

Package content

- Optic fiber coupler

Images

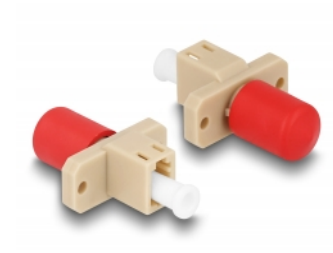

Interface

Connector 1:	1 x LC Simplex female
Connector 2:	1 x ST Simplex female

Technical characteristics

Operating temperature:	-40 °C ~ 80 °C
------------------------	----------------

Physical characteristics

Material:	Plastic
Length:	26.0 mm
Width:	22.0 mm
Height:	9.3 mm
Colour:	beige

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

