

WLAN Dual Band 802.11 ac/ax/a/b/g/n Antenna N jack 6.2 - 8.0 dBi 39.5 cm omnidirectional fixed wall and pole mount outdoor white

Description

This waterproof antenna by Delock allows the usage of different WLAN bands outdoors.



Item no. 12632

EAN: 4043619126323

Country of origin: Taiwan,
Republic of China

Package: White Box

Technical details

- Connector: 1 x N jack waterproof
- Frequency range:
 - 2400 - 2500 MHz
 - 5150 - 5875 MHz
- Antenna gain: 6.2 - 8 dBi
- Impedance: 50 Ohm
- VSWR: 3.0 - 5.0
- Polarisation: linear, vertical
- Operating temperature: -40 °C ~ 85 °C
- Housing material: GFRP
- Length: ca. 395 mm
- Diameter: ca. 27 mm
- Weight: ca. 297 g




System requirements

- Device with one free N port

Package content

- Antenna
- Mounting material

Images

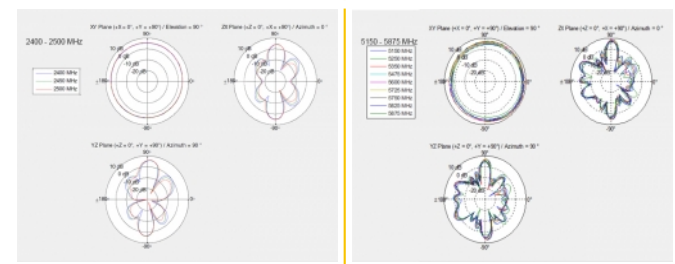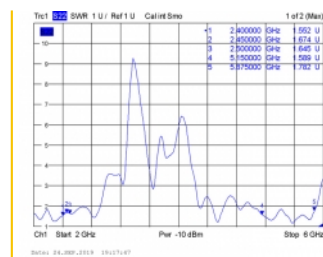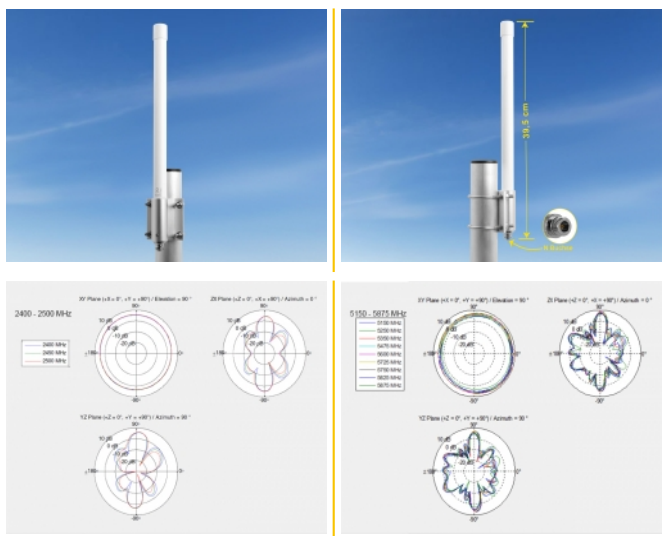

General

Mounting type:	wall pole
Suitable for indoor:	yes
Suitable for outdoor:	yes

Interface

Connector:	N Buchse
------------	----------

Technical characteristics

Frequency range:	5150 - 5875 MHz 2400 - 2500 MHz
Antenna gain:	6.2 - 8.0 dBi
Beam width horizontal:	360°
Beam width vertical:	17°
Impedance:	50 Ω
Operating temperature:	-40 °C ~ 85 °C
Polarisation:	linear vertical
Transmission power:	max. 100 W
VSWR:	2.5

Physical characteristics

Antenna type:	omnidirectional
Housing colour:	white
Housing material:	GFRP
Weight:	297 g mit Befestigungsmaterial
Diameter:	2.6 cm
Length:	395 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

