




Fibre optic diffuse reflection sensor

FT-11-EPA-M3/F2X0,5/2M

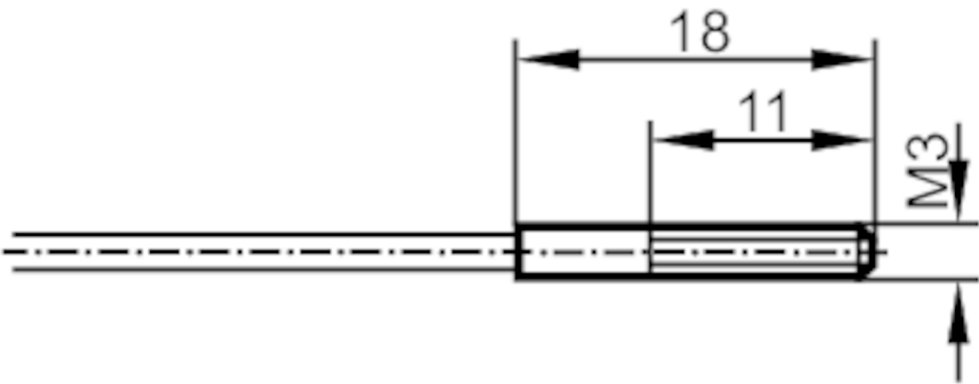

Application		
Function principle		Diffuse reflection sensor
Application		Small bending radius
Detection zone		
Range with fibre optic amplifier type		OB50; OBF; OCF; OO50
OB50		
Range fibre optics	[mm]	20
OBF		
Range fibre optics	[mm]	25
OCF (High Power)		
Range fibre optics	[mm]	250
OO50		
Range fibre optics	[mm]	60
Operating conditions		
Ambient temperature	[°C]	-40...70
Mechanical data		
Weight	[g]	32.5
Version of sensing head		straight
Sensing head thread		M3

E20712



Fibre optic diffuse reflection sensor

FT-11-EPA-M3/F2X0,5/2M

Sensing head length	[mm]	20
Total length	[mm]	2000
Min. bending radius	[mm]	10
Fibre arrangement		⊙
Core diameter	[mm]	2 x 0.5
Fibre material		PMMA
Fibre head material		aluminium
Fibre sheath material		PE

Accessories

Items supplied	hexagon nuts: 2 x M3
	tooth lock washers: 2
	Adapter: OBF
	Adapter: OOF
Accessories (optional)	Cutter for fibre optics:, E20600

Remarks

Pack quantity	1 pcs.
---------------	--------