

Coupler for network cable Cat.6 STP toolfree

Description

With this coupler by Delock, two network cables without plugs can be connected in order to extend or repair them.



Item no. 86928

EAN: 4043619869282

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
2 x LSA block
- Cable routing 180°
- Shielded (STP)
- Cat.6 specification
- TIA-568A/B pinout
- For solid or stranded wire up to 0.644 mm (22 - 24 AWG)
- For cable diameter from 6.0 - 8.5 mm
- Material: zinc die cast
- Dimensions (LxWxH): ca. 59.8 x 12.8 x 10.6 mm

Package content

- Coupler

Images

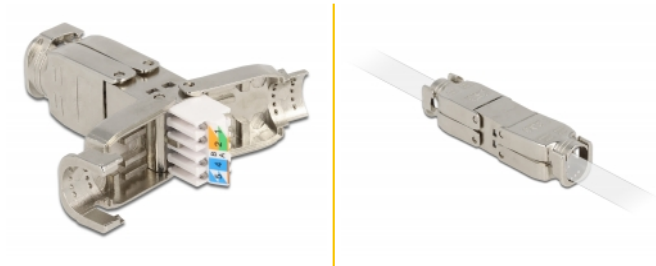

General

Suitable for conductor gauge:	22 - 24 AWG
-------------------------------	-------------

Interface

Connector:	2 x LSA block
------------	---------------

Technical characteristics

Category:	Cat.6
-----------	-------

Physical characteristics

Shielding:	shielded
Length:	59.8 mm
Width:	12.8 mm
Height:	10.6 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

