

Universal Travel Adapter

Experience the ultimate convenience
with just one adapter.

20W



Worldwide
travel



Business
trip abroad



Study
abroad





Safety 10A fuse



World-wide voltage



2A1C 3 Ports fast charging



Compact and portable



AC + USB 4 Devices charging simultaneously

Upgraded 10A Fuse



Supports **2500W** power for various equipment.



laptop



hair dryer



kettle



induction cooker



fan



iron



desk lamp



razor



projector



100-250V World-wide Voltage



Eight Layer Protection



Temperature
protection



Over Current
Protection



Overvoltage
Protection



Overcharge
Protection



Under Voltage
Protection



Short Circuit
Protection



Overload
Protection



Chip
protection

Note:

1. AC appliances can be directly plugged in, with a maximum load capacity of 10A 2500W.
2. This product does not have a voltage conversion function. When using the AC interface, the device voltage needs to be consistent with the local voltage.

Three Ports Fast Charging

A single port with a maximum output of 20W,
four times the power of a traditional 5W charger.




USB Power Output

One port fast charging



20W

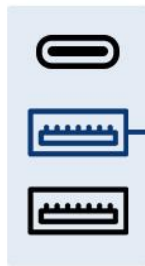


18W



18W

Two-port fast charging

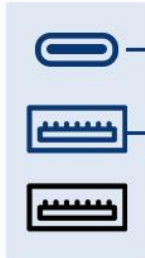

5.0V=3.0A




5.0V=3.0A



5.0V=3.0A


Three port fast charging

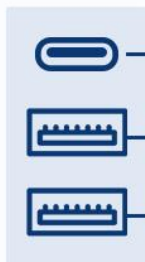

5.0V=3.0A

Charge 4 Devices at Once

Save your clustered desktop.

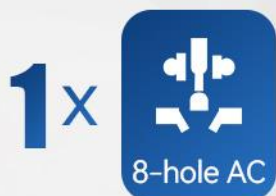

Four Plug Types

An all-in-one charging solution.



Addressing all Your Charging Requirements

The adapter is compatible with most countries worldwide.

US plug



AU plug



UK plug



EU plug



2 pin plug China



3 pin plug China



Note: Please confirm that the rated voltage matches before using.

Easy to Use

Only one plug can be introduced at a time.



Attentions:

1. Please make sure that the button is reset when the button is pushed out and retracted to the bottom, and if the button is not reset, it means that the pug has not been pushed in place and will affect the normal use.
2. Only one plug-type can be used at one time by sliding the knob selection, other plug-pins are locked automatically.

Global Adapter



Light as **141g** $\approx$ Mouse weight

Specifications

Brand	Vention
Name	3-Port USB (C + A + A) Universal Travel Adapter (20W/18W/18W) Black
Model	FJE
Color	Black
Interface	USB-C/USB-A * 2
Rated Output	100-250V~10A Max, 2500W Max
USB-C Output	5.0V $\overline{=}$ 3.0A 15.0W; 9.0V $\overline{=}$ 2.22A 20.0W; 12.0V $\overline{=}$ 1.67A 20.0W
USB-A1/A2 Output	5.0V $\overline{=}$ 3.0A 15.0W; 9.0V $\overline{=}$ 2.0A 18.0W; 12.0V $\overline{=}$ 1.5A 18.0W
USB-C + USB-A1/A2 Output	5.0V $\overline{=}$ 3.0A 15.0W Max
Total Output	20.0W
Fuse Rating	10A MAX
Protocols	
USB-C	PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A
USB-A1/A2	QC 3.0/FCP/AFC/Apple 2.4A
Shell	PC
Fire Rating	UL 94V-0
Packing	Color Box



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.



3-Ports USB (C + A + A) Universal Travel Adapter (20W/18W/18W)

Technical Features

Color	Black
Interface	USB-A+C
Shell	PC
Input	100-250V~50-60Hz, 0.5A
Rated output	100-250V~10A Max, 2500W Max
Output	Output (USB-C): 5.0V= 3.0A (15.0W); 9.0V= 2.22A (20.0W); 12.0V= 1.67A (20.0W) Output (USB-A 1/2): 5.0V= 3.0A (15.0W); 9.0V= 2.0A (18.0W); 12.0V= 1.5A (18.0W) Output (USB-C + USB-A 1/2): 5.0V= 3.0A (15.0W Max)
Total output	20.0W
Protocols (USB-C)	PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A
Protocols (USB)	QC 3.0/FCP/AFC/Apple 2.4A

Color	Art.No.	EAN Code
Black	FJEB0	6922794784338



Package Contents

3-Ports USB (C + A + A) Universal Travel Adapter (20W/18W/18W) x 1

Packaging Information

Packing Dimension	12*8*5.5cm
Packing Weight	0.184kg
Carton Dimension	48*29*31cm
Carton Qty	50pcs
Carton Weight	9.2kg

<https://ventiontech.com/>