

DIGITUS® Dual monitor mount, 2x 27", 2x 8 kg

DA-90349

EAN 4016032382676



Dual Monitor Desk Clamp Mount, 15-27", black max. load 2x8Kg, VESA max100x100

Universal monitor stand for flexible positioning of your monitors at the workstation with simple horizontal and vertical tilting and swivel options. Simply adjust the viewing height to suit your requirements. The monitor stand enables the mounting of LED and LCD monitors of all brands. Simply note the VESA dimensions and the weight of your monitors to select a suitable stand.

Universal dual monitor stand with clamp mount up to 69cm (27")

- Suitable for VESA standard distances 75 x 75 and 100 x 100 mm
- For table tops up to 7.5 cm
- For monitors up to 69cm (27") and 16kg maximum weight
- Separate height adjustment by 15 mm for perfect alignment of your monitors
- Freely adjustable vertical tilt angle up to 45 degrees

- Rotates 360°
- Weight: 5kg
- Dimensions: 726x450x35mm
- Tested & certified ergonomic product - Certified by IGR (Institute for Health and Ergonomics)

Attributes



- Monitor weight (max.): 8 kg
- Mounting method: Clamp-mount
- Number of monitors: 2
- Size of monitors: up to 27"
- VESA mount: 75x75 mm, 100x100 mm

Package contents

- Monitor stand
- Screws for monitor mounting
- Operating instructions

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	3	16.30	48.80	46.50	15.00	34,038.00
Packaging Unit Inside	1	5.43	12.50	47.80	15.00	8,962.50
Packaging Unit Single	1	5.43	12.50	47.80	15.00	8,962.50
Net single without Packaging	1	5.02	12.50	47.80	15.00	8,962.50

More images:

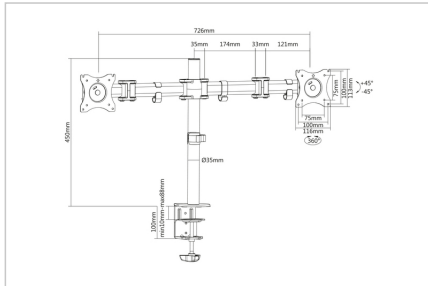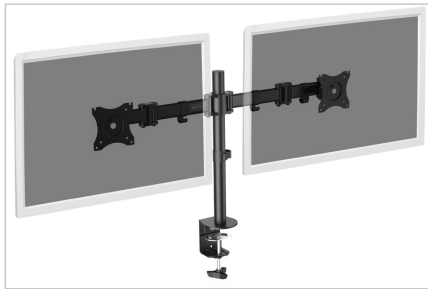

Safety notes

- Please read the entire manual before starting assembly and installation. Please contact your local dealer if you have any questions about the instructions or warnings.
- **CAUTION:** Use with products that exceed the permitted weight may result in damage or possible injury.
- Brackets should be fitted in accordance with the installation instructions. Incorrect installation can result in damage or injury.
- Use safety equipment and suitable tools. The product should only be installed by specialists.
- This product can be installed on timber-framed, solid concrete or stone walls.
- The load-bearing surfaces should be able to safely withstand the entire weight of appliances and all additional components.
- Only use the installation screws supplied and **DO NOT** TIGHTEN the screws **TOO TIGHT**.
- This product contains small parts that can cause a choking hazard if swallowed. Keep these parts away from children.
- Only use this product indoors. Using the product outdoors can lead to injury and damage.
- **IMPORTANT:** Before installation, please check all components received against the components list. If parts are damaged or missing, ask your local dealer for replacement parts.
- **MAINTENANCE:** Check the bracket regularly for safety and stability (preferably every three months).

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schüffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com