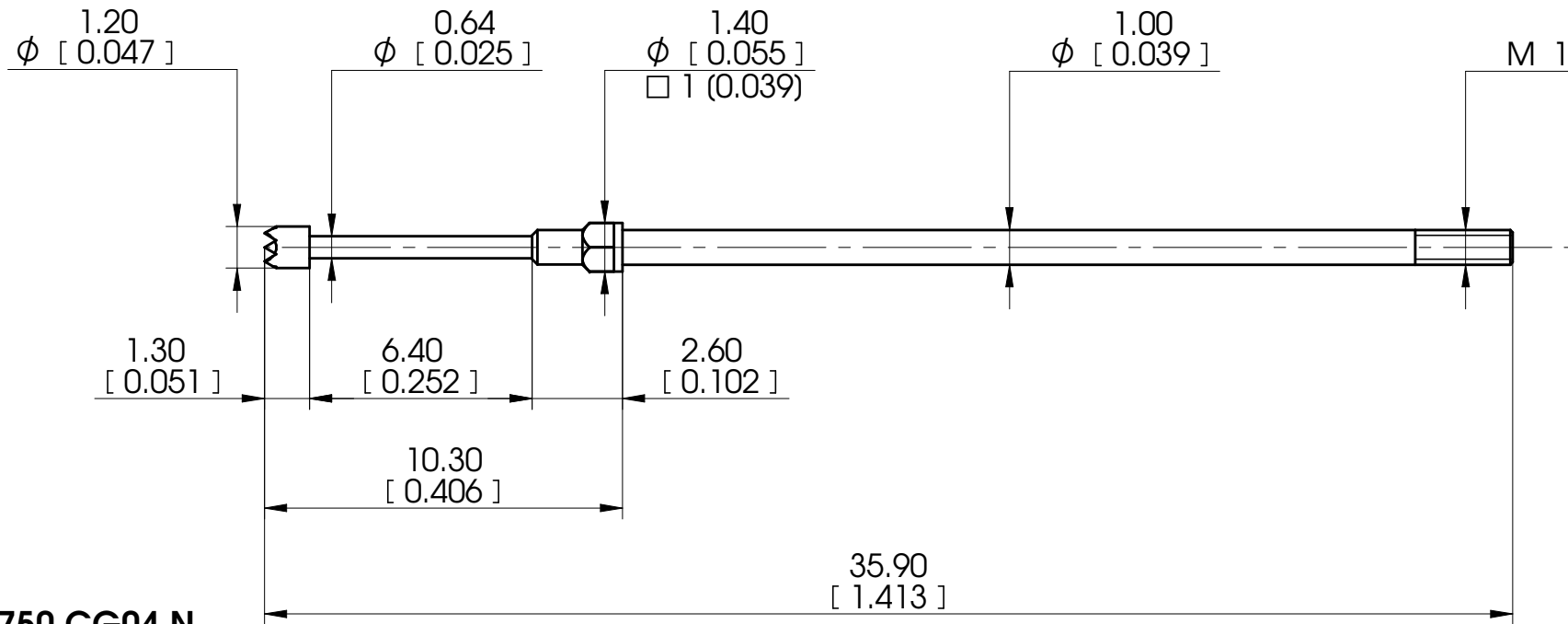


**TT750 CG04 N**

Minimum centers: 1.91 (.075)
 Full travel: 6.35 (.250)
 Working travel: 4.30 (.169)
 Current rating: 3 - 4 A
 Probe resistance: < 20 mΩ
 Plunger material: BeCu - Gold Plated
 Barrel material: Brass - Gold Plated
 Spring material: Music Wire

Operating Temperature: -30 °C up to +80 °C
 (-22 °F up to +176 °F)

Spring force at working stroke: 1.50 N (5.4 oz)

© COPYRIGHT 2019
 EQUIP-TEST KFT.
 ALL RIGHTS RESERVED

This drawing, model, intellectual
 product belongs to Equip-Test Kft.
 Forwarding it to 3rd. party, copying it
 or using for any other purpose
 without the written approval of
 Equip-Test Kft., could entail to legal
 and criminal procedure!

	Name	Date
Designed	V.SZ.	2022.09.12.
Drawed		
Checked		

Note

Catalog Item:
 TT750 CG04 N

Drawing No.:



A4

SHEET 1 OF 1