

TIE10 StickMount


3M Adhesive Cable Tie Base
Black & Natural

3M TAPE

BLACK UV

UL 94 V-2

ROHS COMPLIANT

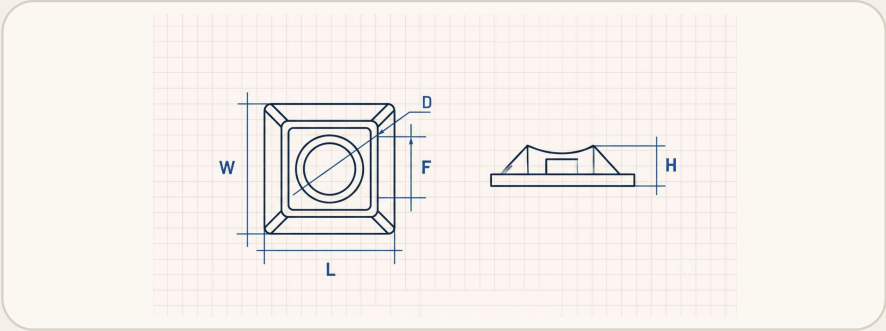

Technical specification

Materials	Black: Polyamide 6.6 + 1% carbon black; Natural: Polyamide 6.6
Hole diameter	5 mm
Colours	Black / Natural
Mounting	Self-adhesive base with 3M tape
UV resistance	Black only
Flammability	UL 94 V-2, self-extinguishing
Working temperature	-40 °C to +85 °C
Resistant to	Solvents, greases and oils

Range & item codes

ITEM CODE	PRODUCT	COLOUR	L (MM)	W (MM)	PCS/PACK	PCS/CARTON
TTP20X20-S/B	3M Adhesive Cable Tie Base 20X20 mm	Black	20	20	100	8,000
TTP20X20-S/W	3M Adhesive Cable Tie Base 20X20 mm	Natural	20	20	100	8,000

Self-adhesive version supplied with 3M tape.